
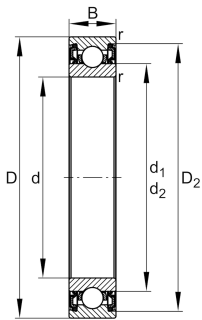


**FAG****61909-2RZ**

Deep groove ball bearing

Deep groove ball bearing 619...-2RZ, single row, shields, steel sheet metal cage

Technical information

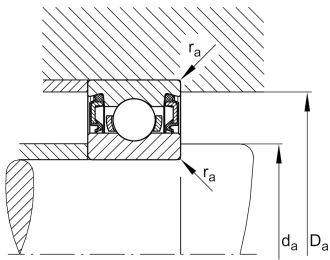

Your current product variant

Sealing	2RZ	Non-contact seal on both sides
Cage	JN	Steel sheet metal
Tolerance class	PN	Normal (PN)
Dimensional / heat stabilization	SN	Rings dimensional stabilized up to 120°
Lubricant	GA13	Ball bearing and insert bearing grease, standard for D>62mm
Radial internal clearance	CN (Group N)	Normal internal clearance
Bore type	Z	Cylindrical

Main Dimensions & Performance Data

d	45 mm	Bore diameter
D	68 mm	Outside diameter
B	12 mm	Width
C _r	15,000 N	Basic dynamic load rating, radial
C _{0r}	10,900 N	Basic static load rating, radial
C _{ur}	650 N	Fatigue load limit, radial
n _G	12,200 1/min	Limiting speed
n _{gr}	8,800 1/min	Reference speed
m	0.13 kg	Weight



Mounting dimensions

$d_{a\ min}$	48.2 mm	Minimum diameter shaft shoulder
$D_{a\ max}$	64.8 mm	Maximum diameter of housing shoulder
$r_{a\ max}$	0.6 mm	Maximum fillet radius

Dimensions

$r_{\min}$	0.6 mm	Minimum chamfer dimension
D_1	60.74 mm	Shoulder diameter outer ring
D_2	62.8 mm	Caliber diameter outer ring
d_1	52.4 mm	Shoulder diameter inner ring

Temperature range

$T_{\min}$	-20 °C	Operating temperature min.
$T_{\max}$	100 °C	Operating temperature max.

Calculation factors

f_0	16	Calculation factor
-------	----	--------------------

Characteristics

	Radial load
	Axial load in one direction
	Axial load in two directions
	Lifetime lubrication, freedom from maintenance
	Grease Lubrication
	Sealed on both sides