



Horizontal board mounting

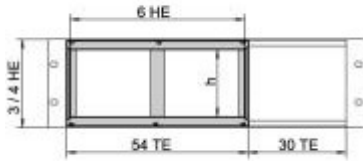

europacPRO

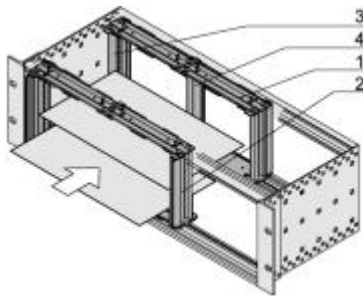

 
(1 TE = 1 HP, 1 HE = 1 U)

Expansion at the front A



Horizontal rail at the front, short lip (H-KD) = flush front panels

Expansion at the rear B



Horizontal rail at the front, long lip (H-LD) = required if IEEE handles are used, for CompactPCI or VME64x systems

Expansion at the rear C



Horizontal rail at rear, recessed (H-VT) = for direct backplane assembly

Expansion rear D

Part no.: 24564-117

Features:

- For horizontal assembly of double euroboards in 3 or 4 U high subrack/case



Technical Information:


Height	Usable height h	Other dimensions and options
3 U	20 HP	front A, rear C

Delivery comprises: kit

Item	Qty	Description
1	4	Support member, Zn die-cast
2	2	Front horizontal rail, Al extrusion, with short lip (H-KD) or long lip (H-LD)
3	2	Rear horizontal rail, Al extrusion, recessed (H-VT)
4	1	Horizontal rail, rear centre, recessed (VT), Al extrusion
5	6	Threaded insert, St, zinc-plated
6	1	Assembly kit incl. instructions

Accessories:

Part no.	Description
24564-109	Front frame, EMC shielded, for horizontal boards H = 128.40 mm

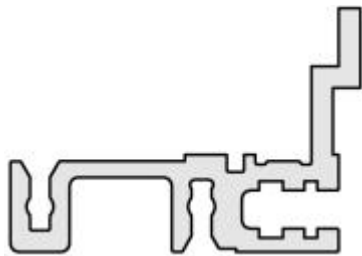

Horizontal rails at rear with Z (H-WZ)
= for assembly of connectors
complying with IEC 60603

Product illustrations are exemplary
illustrations and can deviate from supplied
products.

34564-108	Front frame, unshielded, for horizontal board mounting	
24560-270	Assembly tool for stainless steel EMC gasket, 1 piece	

Note:

- Please order front frame for EMC shielding separately