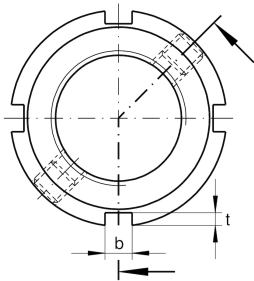
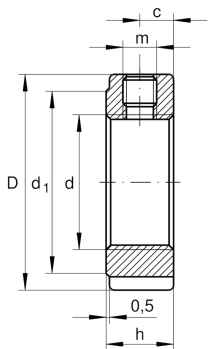
**ZM45** **Precision locknut**

Precision locknut ZM, accessory ZM..

Technical information**Main Dimensions & Performance Data**

d	M45X1,5	Thread
D	65 mm	Outside diameter
h	14 mm	Height
M _A	5 Nm	Mounting torque set screw
F _{aB}	181,000 N	Breaking load, axial
M _L	110 Nm	Breakawag
M _{AL}	65 Nm	Mounting torque reference
M _M	1.48 kg*cm ²	Mass moment of inertia
≈m	0.19 kg	Weight

Dimensions

d ₁	59 mm	Plant diameter outside
t	2.5 mm	Hight retaining slot
b	6 mm	Width retaining slot
c	7 mm	Distance bore
m	M6	Threaded - threaded pin