


Inline filter **OAFa-C-Q4-E-E** Part number: 8212638

FESTO

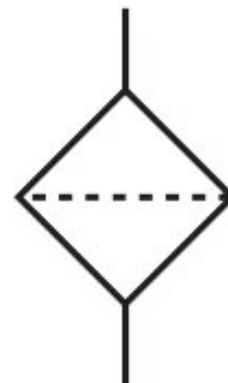

 [General operating condition](#)

Data sheet

Feature	Value
Nominal size	4 mm
Instructions on use	The housing should not be cleaned with polar solvents (such as alcohol).
Mounting position	Any
Grade of filtration	40 µm
Symbol	00991483
Operating pressure	-0.1 MPa ... 1 MPa
Operating pressure	-1 bar ... 10 bar
Operating pressure	-14.5 psi ... 145 psi
Operating medium	Air
Corrosion resistance class CRC	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Suitability for the production of Li-ion batteries	Suitable for battery production with reduced Cu/Zn/Ni values (F1a)
Ambient temperature	0 °C ... 60 °C
Product weight	5.4 g
Type of mounting	Inline installation
Pneumatic connection	For tubing O.D. 4 mm
Note on materials	RoHS compliant
Material seals	HNBR
Material filter	Packaging unit
Material housing	Process automation