

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1210400159](#)
Status: **Active**
Overview: mPm DIN Valve Connectors
Description: mPm DIN Valve Connector, Form A, 2 Pole Plus Ground Position H6/H12, to 2.0m (6.56') PVC Cable Pigtail, Black Nitrile Gasket, 250V

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Industrial Cordsets
Series	121040
Connector End A	Brad mPm DIN A
Connector End B	Pigtail
IP Rating	IP65
Material - Contact	Brass
Overview	mPm DIN Valve Connectors
Product Name	mPm
Region	America, Europe
Type	Single Ended
UPC	883906580711

Physical

Cable Diameter	5.72mm (.225")
Cable Length	2.0m (6.56')
Color - Cable Jacket	Black
Coupling Style	Threaded
Gender	Male-Pigtail
Keyway	None
LED Indicator	No
Material - Cable Jacket	PVC
Material - Connector Body	Polypropylene
Material - Coupling Nut	N/A
Material - Plating Mating	Gold over Nickel
Net Weight	153.630/g
Orientation	90° to Pigtail
Poles	2
Temperature Range - Operating	-25°C to +75°C
Wire Size AWG	N/A
Wire/Cable Type	N/A

Electrical


Current - Maximum per Contact	5.0A
Voltage - Maximum	250V

Material Info

Engineering Number	E152N3N20011
--------------------	--------------

Reference - Drawing Numbers

Sales Drawing	1210400050-000, E152XXXXXXXX
---------------	------------------------------

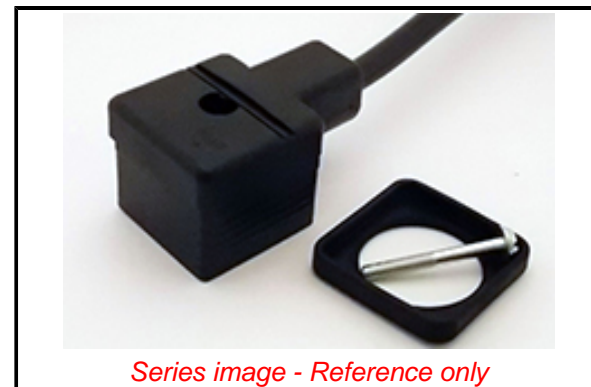

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Contained Per - ED/01/2017 (12 January 2017)
2,4-Di-tert-butyl-6-(5-chlorobenzotriazol-2-yl)p

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[121040 Series](#)