

# powerful performer

HP's brilliant photo-quality colour inkjet printer is designed for creative people who demand that little bit extra of themselves and of the tools they use. A powerful performer with a high duty cycle, the HP Deskjet 940c produces first-class results at high speeds, offering you unlimited scope to realize your most imaginative ideas in your own home.

## imagine the creative possibilities: brilliant photo-quality results

- 2400 x 1200 dpi mode on premium photo papers.
- Incredibly realistic photo images with HP Photoret III precision technology for rich colours and lifelike skin tones from precisely layered ultra-small drops.
- Discover digital imaging with HP's photo printing software. You can print photos at home, modify your images, make photo cards and postcards, create your own photo album, and more.
- Advanced HP Colorsmart III driver enhancements for sharper Internet printing.

## stylish: streamlined design

- The stylish, streamlined design makes this a printer you'll be proud to own.

# brilliant photo quality



## convenient uninterrupted printing with generous 150-sheet paper tray

- Start the job and leave it alone: high-capacity paper tray means fewer printing interruptions. And with a 2,000-page per month duty cycle, this is a tireless worker that copes effortlessly with high demands.

## additional features

- Up to 12 pages per minute in black and up to 10 pages per minute in colour.
- Job cancel button – stop printing immediately to save paper and ink.
- Low-ink indicator – never run out of ink in the middle of a job.
- Create banners, personalized T-shirts and other exciting projects with special HP printing capabilities.
- USB and parallel interfaces.
- For PC and USB-connect Mac.



# hp deskjet 940c printer


## technical specifications

<b>print technology</b>	drop-on-demand thermal inkjet	
<b>printhead nozzles</b>	300 black ink nozzles. Maximum 12 kHz firing frequency 408 colour ink nozzles. Maximum 24 kHz firing frequency	
<b>print speed (pages per minute)</b>	dependent on type and print mode	
	<b>document type</b> <b>draft</b> <b>normal</b> <b>best</b>	
	black text A4      12      6.7      2.9	
	mixed text/colour      10      5.3      1.2	
	graphics A4 10 x 15 cm colour photo (plain paper)	1.0      0.5
	full page colour A4      3.0      0.7      0.3	
<b>print quality</b>	<b>output</b> <b>best</b> black      600 dpi with black pigmented ink colour      2400 x 1200 dpi using premium photo paper	
<b>colour technology</b>	HP Photorel III precision technology, HP Colorsmart III	
<b>operating systems compatibility</b>	Microsoft® Windows® (3.1x, 95, 98, Me, NT 4.0, 2000 Professional, XP Home and Professional), MS-DOS, USB Mac OS 8.1 and above (USB-connect Macintosh® only)	
<b>minimum system requirements</b>	Microsoft® Windows® XP Home and Professional: Pentium® 233 Mhz, 128 MB RAM, Microsoft® Windows® 2000 Professional: Pentium® 133 Mhz, 64 MB RAM, Microsoft® Windows® Me: Pentium 150 Mhz, 32 MB RAM, Microsoft® Windows® 95, 98, NT 4.0: Pentium® 66 Mhz, 32 MB RAM, MS-DOS 3.3 or above: 486 processor, 4MB RAM, Mac OS X: visit <a href="http://www.hp.com/go/mac-connect">www.hp.com/go/mac-connect</a> , Mac OS 8.6 or above: 64 MB RAM** **MS-DOS 3.3 or above, Windows® 3.1x, Mac OS 8.1 or above, and Windows® 2000 Professional or above with limited functionality	
<b>memory</b>	2 MB built-in RAM	
<b>printer languages</b>	HP PCL level 3 enhanced	
<b>typefaces</b>	8 built-in fonts, 4 each in Portrait and Landscape orientations: CG Times, CG Times Italic, Univers, Univers Italic, Courier, Courier Italic, Letter Gothic, Letter Gothic Italic	
<b>cartridge alignment</b>	+/- 0.002 in manual pen alignment	
<b>duty cycle</b>	2,000 pages per month	
<b>recommended media weight</b>	paper: 60 to 90 g/m <sup>2</sup> , banner paper: 60 to 90 g/m <sup>2</sup> , envelopes: 75 to 90 g/m <sup>2</sup> , cards: 110 to 200 g/m <sup>2</sup> ; 0.3 mm maximum thickness, photo: all	
<b>media sizes</b>	<b>standard:</b> A4, A5, B5, DL, C6, A6 <b>custom:</b> 77 to 216 mm, 77 to 356 mm	
<b>media types</b>	paper (plain, inkjet, photo, glossy), envelopes, transparencies, labels, cards, banner paper	
<b>media handling/input</b>	<b>media type</b> <b>up to</b> sheets      150 banners      20 envelopes      15 cards      30 transparencies      25 labels/A4 sheets      20	
<b>paper input trays</b>	150 sheet paper tray	
<b>media handling/output</b>	50 sheets output	
<b>power requirements</b>	Input voltage 100 - 240 AC (+/- 10 %), 50/60 Hz (+/- 3 Hz)	
<b>power consumption</b>	2 watts maximum when off 4 watts average non-printing 25 watts average when printing	
<b>interface and connectivity</b>	IEEE 1284, Universal Serial Bus (Windows® 98, Me, 2000, XP and USB-connect Macintosh®)	
<b>software included</b>	HP photo printing software for easy photo editing, printing, adjusting, creating your own photo album and more (for PC only, Win 95/98, Me, NT 4.0, 2000)	
<b>dimensions (w x d x h)</b>	<b>out of package:</b> 440 x 370 x 196 mm <b>packaged:</b> 498 x 245 x 440 mm	
<b>product weight (without cartridges)</b>	<b>out of package:</b> 5.85 kg <b>packaged:</b> 8.2 kg	
<b>operating environment</b>	<b>environmental ranges</b> operating temperature: 5 to 40° C operating humidity: 15 to 80% RH non-condensing operating humidity recommended: 20 to 80% RH non-condensing recommended operating temperature: 15 to 35° C storage temperature: -40° to 60° C <b>noise level per ISO 9296</b> sound power: 5.9 B(A), sound pressure: 46 dB(A)	
<b>ENERGY STAR</b>	yes	
<b>warranty</b>	1 year	

## ordering information

<b>number</b>	<b>description</b>	<b>cables</b>
c6431f	hp deskjet 940c colour printer, hp black inkjet print cartridge, hp tri-colour inkjet print cartridge, power cord, CD-ROM containing printer software and HP photo printing software, user's guide, setup poster	c2950a IEEE-1284-compliant A-B parallel cable 2 m
		c2951a IEEE-1284-compliant A-B parallel cable 3 m
		c6518a hp USB cable 2 m
<b>supplies</b>		
c6615de	hp no 15 black inkjet print cartridge (25 ml)	
c6615ne	hp no. 15 black inkjet print cartridge (14 ml)	
c6578ae	hp no. 78 tri-colour inkjet print cartridge (38 ml)	
c6578de	hp no. 78 tri-colour inkjet print cartridge (19 ml)	
<b>media</b>		
c5977b	hp bright white inkjet paper, A4 250 sheets	
c1825a	hp bright white inkjet paper, A4 500 sheets	
51634z	hp premium inkjet coated paper, A4 200 sheets	
c1853a	hp premium inkjet heavyweight paper, A4 100 sheets	
c6818a	hp professional brochures + flyer paper, A4 50 sheets	
c3831a	hp premium inkjet glossy paper, A4 10 sheets	
c3837a	hp premium inkjet glossy paper, A4 50 sheets	
c3832a	hp premium transparency film, A4 20 sheets	
c3835a	hp premium transparency film, A4 50 sheets	
c1847a	hp two-sided photo paper, A4 20 sheets	
c6040a	hp premium photo paper, A4 15 sheets	
c7040a	hp premium photo paper, A4 50 sheets	
c6832a	hp premium plus photo paper glossy, A4 20 sheets	
c6951a	hp premium plus photo paper matte, A4 20 sheets	
c6945a	hp premium plus photo paper glossy, 10 x 15 cm 20 sheets	
c6984a	hp photo-quality inkjet paper, A4 25 sheets	
c6042a	hp matte greeting cards, quarter-fold 20 cards/envelopes	
c6045a	hp glossy greeting cards, half-fold 10 cards/envelopes	
c7014a	hp colorfast photo paper, A4 25 sheets	
c6829a	hp textured greeting cards, cream, half-fold 20 cards/envelopes	
c6050a	hp iron-on t-shirt transfers, 10 sheets	
c1821a	hp banner paper, A4 5 banners	
chp210	hp printing paper, A4 500 sheets	

Examples  
 1 Black text  
 2 Mixed text/ colour graphics  
 3 10 x 15 cm colour photo  
 4 Full page colour

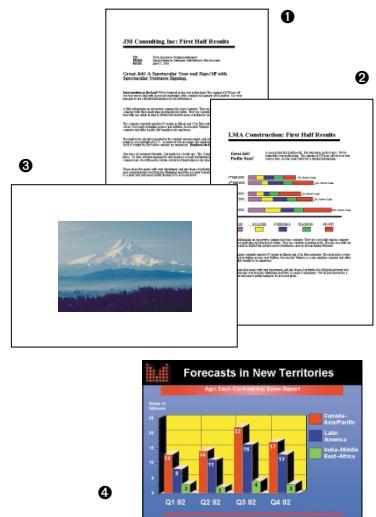

Windows is a U.S. trademark of Microsoft Corp. All other brand and product names are trademarks or registered trademarks of their respective companies.

The information in this document is subject to change without notice.

The ENERGY STAR emblem does not represent EPA endorsement of any product or service.

© Hewlett-Packard Company  
Printed in the Netherlands 07/01

5980-5375EEE

<http://www.hp.com>

For more information, please call your local HP sales office or representative: **Austria:** 0810/006080 (local rate call), **Azerbaijan:** +7 (99412) 973 561, **Belgium:** (02) 778 34 00, **Luxembourg:** (+352) 263 160 34, **Bulgaria:** (+359) 2960 1940, **CIS:** (007) 095 797 3500, **Croatia and Slovenia:** (+385 1) 60 60 200, **Czech Republic:** (00 420 2) 613 07 111 (Prague), **Denmark:** 45991125, **Dubai (Gulf Region):** (971) 488 15 456, **East Central Europe (Vienna HQ plus Albania):** (+43) 1-250 00, **Finland:** (09) 88721, **France:** (1) 69 82 6060, **Germany:** 0180 532 6222 (0.24 DM per minute), **Greece:** (01) 619 64 11, **Hungary:** (+36) 1 382-1111, **Iceland:** (354) 570 1000, **Ireland:** (00) 353 1 61 58 200, **Israel:** (972) 9 952 4848, **Italy:** (02) 92121, **Kazakhstan:** +7 (3272) 980 824, **Morocco (African Region):** (212) 222 21340, **Netherlands:** (020) 5476666, **Norway:** 22 735600, **Poland:** infolinia 0-801 607 607 (0.29 zl + VAT/min), **Portugal:** (808) 206 001, **Romania:** (+401) 250 6197, **RSA:** (27) 11 806 1000, **Slovakia:** (+421 7) 68 20 90 11, **Spain:** (91) 6311600, **Sweden:** (08) 444 2000, **Switzerland:** 0848 88 44 66, **Turkey:** +90 (216) 579 71 71, **UK:** (0990) 474747, **Ukraine:** 380 44 490 61 20, **Uzbekistan:** +7 (99871) 169 1488, **Yugoslavia:** +7 (044) 490 6120, **Multi Country Operations (MCO) (Geneva):** (22) 7804111, **European Headquarters (Geneva):** (22) 7808111.

