

SEK-18 ACC.STRAIN RELIEF CLAMP FE 24P

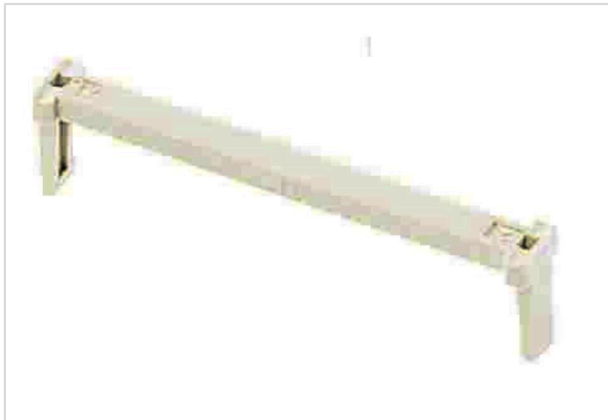


Image is for illustration purposes only. Please refer to product description.

Part number	09 18 524 9002
Specification	SEK-18 ACC.STRAIN RELIEF CLAMP FE 24P
HARTING eCatalogue	https://harting.com/09185249002

Identification

Category	Accessories
Series	SEK
Type of accessory	Strain relief clamp

Version

Size	24 poles
------	----------

Material properties

RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
Fire protection on railway vehicles	EN 45545-2 (2020-08)
Requirement set with Hazard Levels	R26

Specifications and approvals

UL / CSA	UL 1977 ECBT2.E102079 CSA-C22.2 No. 182.3 ECBT8.E102079
----------	------------------------------------------------------------

Commercial data

Packaging size	100
Net weight	0.98 g



Pushing Performance
Since 1945

Commercial data

Country of origin	China
European customs tariff number	85366990
GTIN	5713140030848
eCl@ss	27440292 Connector component (accessories)
ETIM	EC002943
UNSPSC 24.0	39121400