

Actuator

45-
2F0T.1010.000

Distribution by
Rs-online



<https://rs-online.eao.com/p/45-2F0T.1010.000>

Your product:



45-2F0T.1010.000 Actuator

FRONT

Front dimension:	Ø 29,5 mm
Front form:	Round
Front bezel colour:	Black
Front bezel material:	Plastic

MOUNTING

Design:	Raised
Mounting cut-out:	Ø 22.3 mm
Mounting type:	Panel mounting

OPERATING-/INDICATION PART

Lever colour:	Black
Lever material:	plastic

MECHANICAL CHARACTERISTIC

Switching action:	Momentary
Mechanical lifetime:	250 000 cycles of operation per direction of actuation
Operating frequency:	1 800/h
Weight:	0.03 kg

AMBIENT CONDITION

IP front protection:	IP65, IP67
----------------------	------------

Operating temperature:	– 25 °C ... + 70 °C
Storage temperature:	– 40 °C ... + 80 °C
Shock resistance:	According to IEC 60068-2-27: Sinusoidal half-wave 50 g / 11 ms
Vibration resistance:	According to IEC 60068-2-6: 10 ... 500 Hz: 5 g
Climate resistance:	During operation according to IEC 60721: 3K6, 3C3, 3S2, 3M6, 3B2

CERTIFICATE

REACH: REACH compliant

RoHS: RoHS compliant

OTHER


Short Description: Actuator, Ø 22.3 mm, Ø 29,5 mm, Black, Round, Black, Plastic, Momentary, IP65, IP67

Housing material: Plastic


Product attributes: 2 positions (L-R)

Hints: Lockable only in center position

Wiring diagrams:

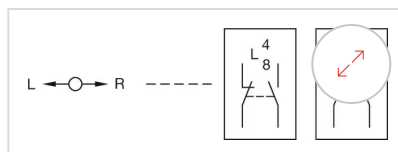

Mounting cut-outs:

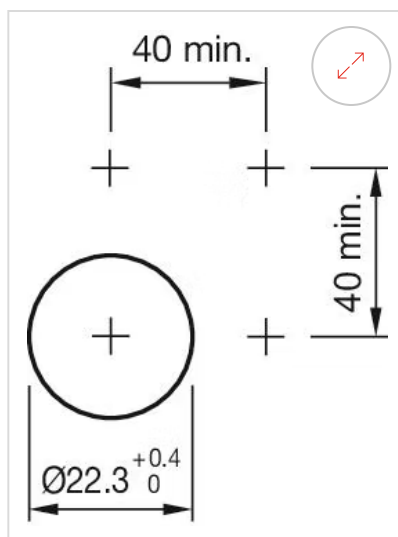

Dimension drawings:

