

## Tapered parallel male thread twin coupler



### Technical characteristics

**Technology:** "One push" safety system (avoids hose whip)

**Operating pressure:** 2 to 12 bar

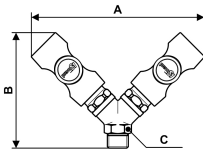
**Flow rate at 6 bar:** 833 l/min ( $\Delta P = 0,6$  bar)

**ID Passage:** 6 mm

**Temperature:** -15°C to +70°C

**Construction:** Composite body

**Highlight:** Anti-static, Non scratch

	A	B	C	BSPT male thread	Parts Numbers
	(mm)	(mm)	(mm)		
	134	88	17	R 1/4	ISI 068151
	140	92	20	R 3/8	ISI 068152
	150	104	25	R 1/2	ISI 068153