


CCT-RF-KIT

RF wireless LED remote controller



CCT-RF-RCX

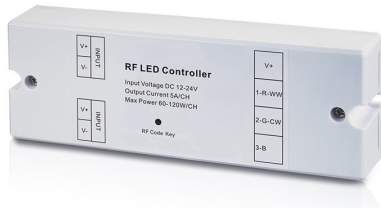

CCT-RF-3x5A

Key Features:



- Suitable for indoor LED lighting
- User-friendly interface, easy and simple operation
- Full Tone Adjustment
- Dimming Control
- Simple Modes
- Smooth Tone Control Curve
- Operating Frequency 434MHz/868MHz/915MHz

RF WIRELESS CONTROLLER SPECIFICATION

Model No.	CCT-RF-RCX	CCT-RF-3x5A
Voltage	4.5V ~ 3xAAA Batteries (not included)	12 ~ 24Vdc
Max Load Current	3 x 5A	3 x 5A
Rated Power		3 x (60 ~ 120) W
Load Type		0.04 ~ 0.1W
Operation Frequency	434MHz/868MHz/915MHz	34MHz/868MHz/915MHz
Operating Temperature	-0°C ~ +40°C	-0°C ~ +40°C
Relative Humidity	8% ~ 80%	8% ~ 80%
Ingress Protection	IP20	IP20
Dimensions	120 x 48 x 17.6mm	145 x 46.5 x 16mm




Mechanical Diagrams

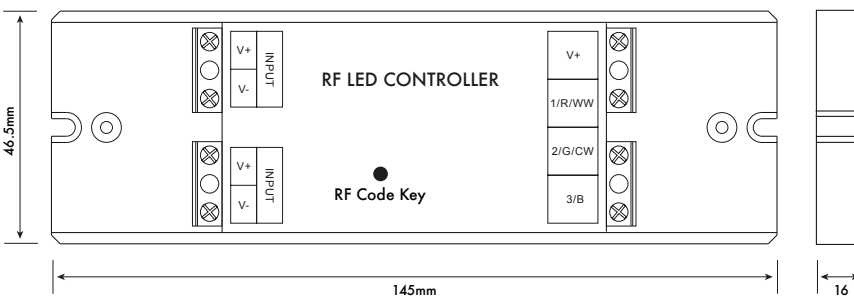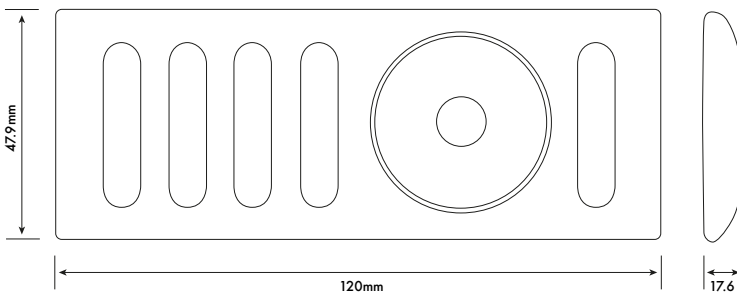

LED Flexi Tape Tuneable White

Wiring Diagram

With dual color LED strip

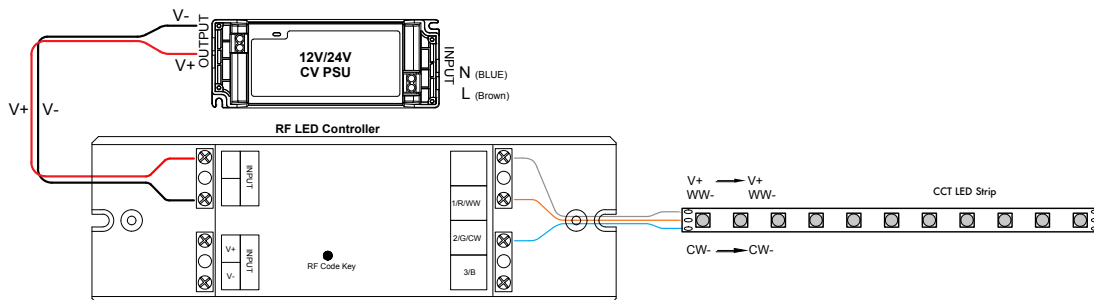

With dual color LED strip

