


Features

- Conforms to ANSI/TIA-568.2-D & ISO/IEC 11801-1
- HDPE Insulation
- Mylar & AL-Mylar Tape Construction
- UL E164469 Approved Cable
- Backwards Compatible to CAT 3 & CAT 5
- Operation Temp -20c - 60c
- Conductor DC Resistance $\leq 93.8 \Omega$ /1000m

RS PRO Ethernet Cable

RS Stock No.: 0199195

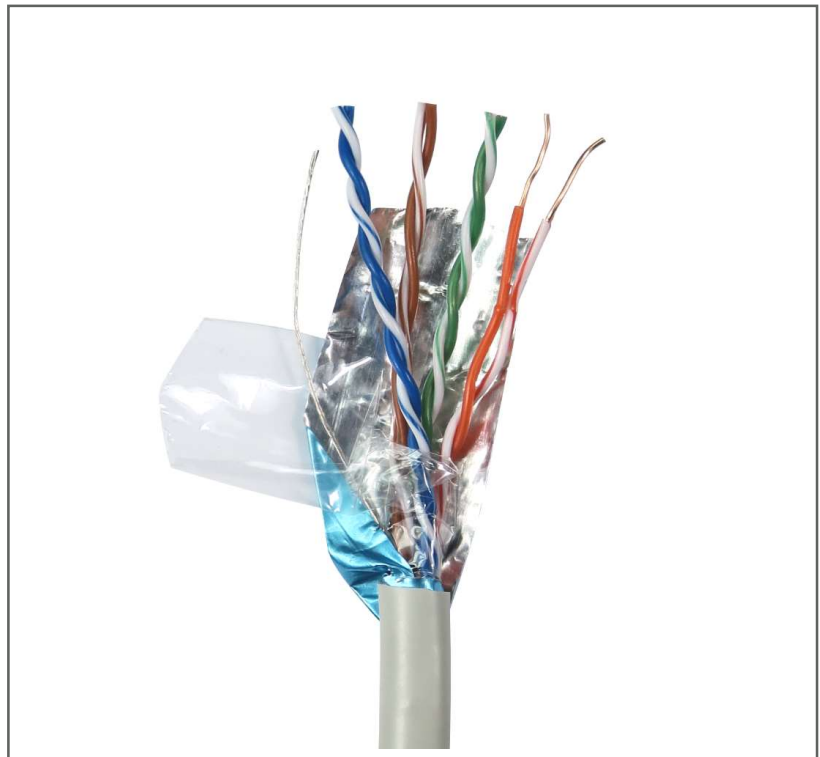

RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

A flexible variant designed for demanding applications. The RS Pro Unterminated Cat5e type cables have primary application use for both home and office computer networks. This cable is compliance with CE, UKCA, RoHS, REACH and UL standards. It features an IP67 rating, ensuring it is protected against dust and water immersion. It has 8 core strands made from PVC, providing reliable fire behaviour. The conductor strand type is solid, and it utilizes a 24 American Wire Gauge (AWG), making it suitable for various applications requiring robust connectivity.

General Specification

LAN Category	Cat5e
Length	305m
Terminated/Unterminated	Unterminated
Shield Type	F/UTP
Shielded/Unshielded	Shielded
CPR Certification	Eca
Coding	T568B
Sheath Colour	Grey
Outer Sheath Material	PVC
IP Rating	IP67
Core Strands	8
Fire Behaviour	PVC
Voltage Rating	300V
Conductor Strand Type	Solid
American Wire Gauge	24AWG
Cable Shape	Round

Number of Strands	8
Outer Diameter (mm)	6mm
Cross Sectional Area (mm)	0.2028mm
Current Rating (A)	3.5A
Applications	Cat5e type cables have primary application use for both home and office computer networks