


Axial kit
EAMM-A-N48-60P
Part number: 8197468

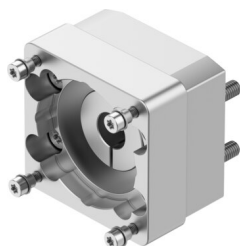

 [General operating condition](#)

Data sheet

Feature	Value
Nominal length	41 mm
Mounting position	Any
Max. rotational speed	8000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	14.5 kgmm ²
Transmittable torque	12.5 Nm
Product weight	328 g
Interface code, actuator	N48
Interface code, motor in	60P 60PA
Note on materials	RoHS compliant