



家庭用コンセントからUSB電源出力に変換できる最大2Aの出力に対応したAC充電器。2A・ブラック。

ACA-IP87BK

USB充電器（2A・ブラック）

JANコード 4969887505830




仕様

カラー	ブラック
定格入力	AC100~240V 50/60Hz
定格出力	DC5V/2A ※iPadなどApple機器に対しては充電器の仕様上1Aの給電になります。
ポート数	USB Aポート×1
USB出力端子形状	USB A
材質	PC
サイズ	W38×D22×H48mm
重量	約40g
プラグ形状	2P

特長

家庭用コンセントから2AのUSB電源出力に変換できるAC充電器です。
過電流保護や短絡保護などを搭載し、安全に使用することができます。
絶縁キャップ付きACプラグを採用し、トラッキング火災を予防します。

※電気用品安全法（PSE）技術基準適合品です。

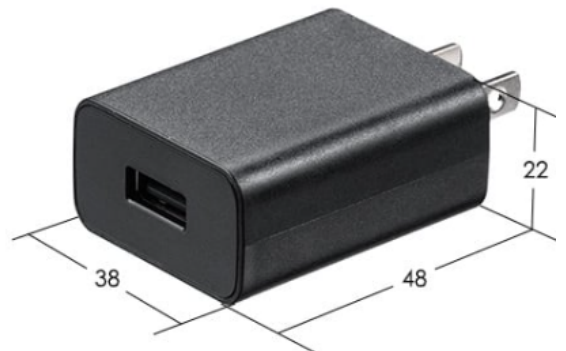

This AC charger converts power from a household outlet to USB power output, supporting up to 2A of power output. 2A, Black.

ACA-IP87BK

USB Charger (2A, Black)

Specifications

- Color : Black
- Rated Input: AC 100-240V 50/60Hz
- Rated Output : DC 5V/2A
 - ※Due to the charger's specifications, power supply for Apple devices such as iPads is limited to 1A.
- Number of Ports : 1 x USB-A
- USB Output Terminal : USB-A
- Material : PC
- Dimensions : W38 x D22 x H48mm
- Weight : Approx. 40g
- Plug Type : 2-Pin

Features

- This AC charger converts power from a household outlet into 2A USB power output.
 - Equipped with overcurrent and short-circuit protection, it ensures safe use.
 - The AC plug features an insulating cap to prevent tracking fires.
- ※Complies with the technical standards of the Electrical Appliance and Material Safety Act (PSE).