

PRODUCTION: SEPT 2015

Graphic display for easy editing of labels


One touch function keys for ease of use

Flat keyboard makes text entry easy

20mm/second print speed for quicker labelling

Template library for creative labelling

More fonts, frames and symbols than competition

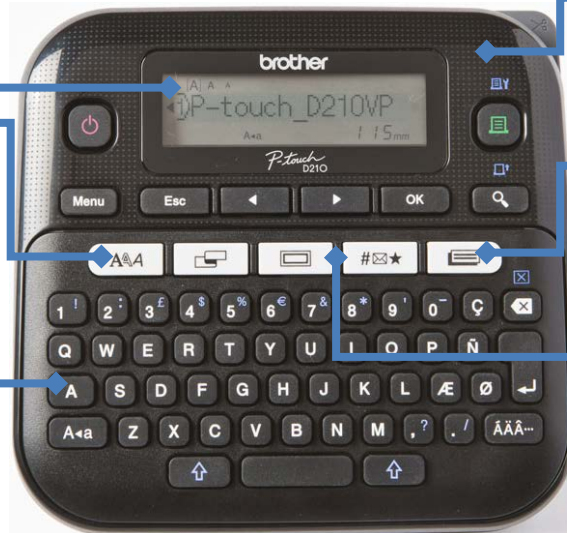

Also includes:

- Carry case
- AC adapter
- 12mm black on white TZe tape (4m)



## Main features at a glance:

### Graphic LCD display

- Easy-to-read text, and the ability to preview your label before printing.

### One-touch function keys

- Quickly access frequently used functions to speed up label creation.

### Flat keyboard

- Reduces typing mistakes, and makes it just as easy to use in the hand, as well as on your desk.

### High speed print

- 20mm/second print speed.

### Template library

- 10 “Text labels” and 7 “Pattern labels” for creative labelling.

### High specifications

- More built-in fonts, frames and symbols than the competition.

### Multiple power options

- Supplied with an AC adaptor.
- Also works with 6 x AAA batteries (not supplied).

# PT-D210VP DATASHEET

## General

|                         |  |
|-------------------------|--|
| <b>Carton contents</b>  | PT-D210 labelling machine<br>12mm TZe black on white tape cassette (4m)<br>AC adapter (AD-24ES)<br>Documentation<br>Carry case   |
| <b>Language support</b> | English, German, French, Dutch, Italian, Spanish,<br>Portuguese, Danish, Norwegian, Swedish,<br>Finnish, Hungarian, Czech, Polish, Romanian,<br>Slovenian, Slovakian, Croatian, Brazilian<br>Portuguese, Turkish |

## Dimensions & Weights

|                       |                                       |
|-----------------------|---------------------------------------|
| <b>Without carton</b> | 157 (w) x 149 (d) x 68 (h)   0.49 kg  |
| <b>With carton</b>    | 308 (w) x 253 (d) x 319 (h)   1.62 kg |
| <b>Master carton</b>  | 347 (w) x 345 (d) x 318 (h)   6.30kg  |

## Built In Features

|                                 |   |
|---------------------------------|---|
| <b>Keyboard</b>                 | 62 Rubber Keys QWERTY / QWERTZ / AZERTY |
| <b>Dedicated number keypad</b>  | Yes                                     |
| <b>Interfaces</b>               | None                                    |
| <b>Operating system support</b> | N/A                                     |
| <b>Display type</b>             | Graphic display with label preview      |
| <b>Display resolution</b>       | 16 characters by 1 line   128 x 16 dots |
| <b>Printing speed</b>           | Up to 20mm/second                       |
| <b>Print resolution</b>         | 180dpi                                  |
| <b>Maximum print height</b>     | 9.0mm                                   |
| <b>Cutter type</b>              | Manual cutter                           |
| <b>Label length</b>             | 30mm minimum   300mm maximum            |
| <b>Maximum lines per label</b>  | 2                                       |
| <b>Vertical text printing</b>   | Yes                                     |
| <b>Mirror printing</b>          | Yes                                     |
| <b>Copies</b>                   | 1 to 9                                  |
| <b>Numbering</b>                | Yes (1-99)                              |

## Label Creation

|                         |  |
|-------------------------|--|
| <b>Fonts</b>            | 14   Helsinki, Brussels, Belgium, Florida,<br>Los Angeles, San Diego, US, Calgary, Atlanta,<br>Adams, Brunei, Istanbul, Sofia, Germany |
| <b>Font styles</b>      | 9   Normal, Bold, Outline, Italic, Shadow, Solid,<br>Italic Bold, Italic Outline, Italic Shadow  |
| <b>Font sizes</b>       | 3  |
| <b>Symbols</b>          | 617  |
| <b>Frames</b>           | 97   |
| <b>Template library</b> | 10 "Text labels"   7 "Pattern labels"  |

## Memory

|                                  |                                   |
|----------------------------------|-----------------------------------|
| <b>Max. characters per label</b> | 80 characters                     |
| <b>Label memory locations</b>    | 30 areas (2,400 characters total) |

## Supplies

|                    |                  |
|--------------------|------------------|
| <b>Tape type</b>   | TZe              |
| <b>Tape widths</b> | 3.5, 6, 9 & 12mm |

## Optional Accessories

|                   |  |
|-------------------|--|
| <b>Batteries</b>  | 6 x AAA (LR03) alkaline<br>6 x AAA (HR03) rechargeable |
| <b>AC adaptor</b> | AD-24ES  |