


Datasheet

RS 811-7106

Basic 2U Horizontal Silk Screened PDU with:-

- 1 x Australian Socket
- 1 x UK BS1363 Socket
- 1 x Danish Socket
- 1 x BS546 Socket
- 1 x German Schuko Socket
- 1 x Swiss Socket
- 1 x Italian Socket
- 3 Metre Lead
- 230V/16A German Schuko Plug
- Grey Finish (RAL7044)

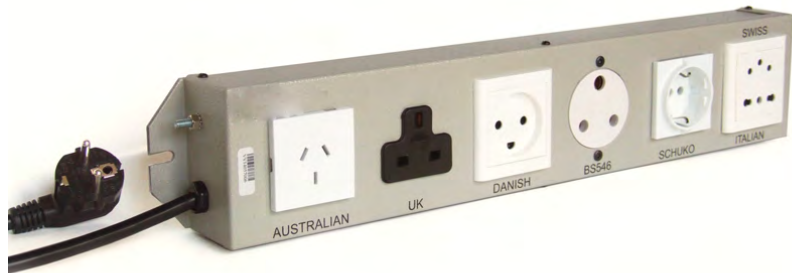

Specifications:

Quantity Of Inputs	1
Voltage	230V
Amperage	16A
VA per Input (Load Capacity)	3.6kW
Frequency	50/60 Hz
Over Current Protection	None
Switch	None
Power Cable Wire Gauge	1.5mm ² H07RN-F
Power Cable Length	3M
Plug Type	Schuko, 16A, 250V
Receptacle/Socket Type #1	Australian
Quantity on Face #1	1
Style #1	Individual
Maximum Output per Receptacle/Socket #1	10A per receptacle bank
Voltage per Receptacle/Socket #1	230V
Receptacle/Socket Type #2	UK BS1363
Quantity on Face #1	1
Style #2	Individual
Maximum Output per Receptacle/Socket #2	13A per receptacle bank
Voltage per Receptacle/Socket #2	230V
Receptacle/Socket Type #3	Danish
Quantity on Face #1	1



Style #3	Individual
Maximum Output per Receptacle/Socket #3	13A per receptacle bank
Voltage per Receptacle/Socket #3	230V
Receptacle/Socket Type #4	BS546
Quantity on Face #1	1
Style #4	Individual
Maximum Output per Receptacle/Socket #4	15A per receptacle bank
Voltage per Receptacle/Socket #4	230V
Receptacle/Socket Type #5	German Schuko
Quantity on Face #1	1
Style #5	Individual
Maximum Output per Receptacle/Socket #5	16A per receptacle bank
Voltage per Receptacle/Socket #5	230V
Receptacle/Socket Type #6	Swiss
Quantity on Face #1	1
Style #6	Individual
Maximum Output per Receptacle/Socket #6	10A per receptacle bank
Voltage per Receptacle/Socket #6	230V
Receptacle/Socket Type #7	Italian
Quantity on Face #1	1
Style #7	Individual
Maximum Output per Receptacle/Socket #7	16A per receptacle bank
Voltage per Receptacle/Socket #7	230V
Heavy Steel - Powder Coat	Yes – RAL 7044
Configuration	2U Horizontal
Product Warranty	Lifetime
Chassis Dimensions (LxWxD)	483mm x 88mm x 50mm