


push-in Y-connector
NPQP-Y-Q12-Q10-FD-P10
 Part number: 133127

FESTO

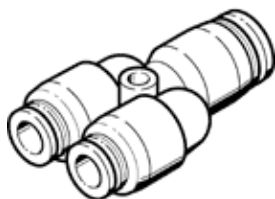

Data sheet

Feature	Value
Size	Standard
Nominal size	5.9 mm
Container size	10
Design structure	Push/pull principle
Temperature dependent operating pressure	-0.95 ... 10 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	4 - Very high corrosion stress
Food-safe	See Supplementary material information
Ambient temperature	-20 ... 60 °C
Product weight	28.5 g
Pneumatic connection, port 1	for tubing, 12mm outside diameter
Pneumatic connection, port 2	For tubing outside diameter 10 mm
Materials note	Contains PWIS substances Conforms to RoHS
Material housing	PP
Material of tube retaining claw	High alloy steel, non-corrosive