

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [38700-6104](#)  
**Status:** **Active**  
**Overview:** Beau™ Barrier Strips  
**Description:** 8.26mm Pitch Beau™ PCB Terminal Strip, with Mounting Ends, 4 Circuits

**Documents:**

[3D Model](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Drawing \(PDF\)](#)

**General**

|                |                                      |
|----------------|--------------------------------------|
| Product Family | Terminal Blocks                      |
| Series         | <a href="#">38700</a>                |
| Application    | N/A                                  |
| Component Type | One Piece                            |
| Overview       | <a href="#">Beau™ Barrier Strips</a> |
| Product Name   | Fixed Mount Barrier                  |
| Type           | Barrier Strip                        |
| UPC            | 800756312590                         |

**Physical**

|                                |                    |
|--------------------------------|--------------------|
| Circuits (Loaded)              | 4                  |
| Circuits (maximum)             | 4                  |
| Color - Resin                  | Black              |
| Entry Angle                    | Horizontal         |
| Lock to Mating Part            | None               |
| Material - Metal               | Brass              |
| Material - Plating Mating      | Tin                |
| Material - Plating Termination | Tin                |
| Material - Resin               | Polyester          |
| Net Weight                     | 9.412/g            |
| Number of Rows                 | 1                  |
| Orientation                    | Horizontal         |
| PC Tail Length                 | 3.56mm             |
| PCB Retention                  | Yes                |
| Panel Mount                    | No                 |
| Pitch - Mating Interface       | 8.26mm             |
| Pitch - Termination Interface  | 8.26mm             |
| Plating min - Mating           | 3.810µm            |
| Plating min - Termination      | 3.810µm            |
| Polarized to Mating Part       | No                 |
| Shrouded                       | Dual-Barrier       |
| Stackable                      | Yes                |
| Surface Mount Compatible (SMC) | No                 |
| Temperature Range - Operating  | -40°C to +130°C    |
| Termination Interface: Style   | Through Hole       |
| Wire Size AWG                  | 14, 16, 18, 20, 22 |
| Wire Size mm²                  | 0.50 - 1.50        |

**Electrical**


|                               |      |
|-------------------------------|------|
| Current - Maximum per Contact | 15A  |
| Voltage - Maximum             | 300V |

**Solder Process Data**

|                              |                        |
|------------------------------|------------------------|
| Lead-free Process Capability | Wave Capable (TH only) |
|------------------------------|------------------------|

**Material Info**

|                 |       |
|-----------------|-------|
| Old Part Number | 70504 |
|-----------------|-------|

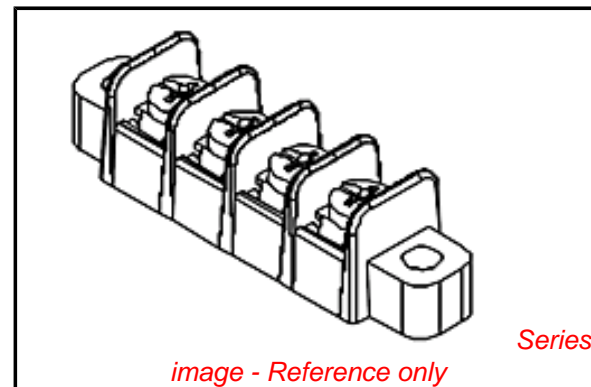

**EU RoHS**

**ELV and RoHS Compliant**  
**REACH SVHC**  
**Contains SVHC: No**  
**Low-Halogen Status**  
**Not Low-Halogen**

**China RoHS**



**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

**Search Parts in this Series**

[38700Series](#)

**Mates With**

N/A

**Reference - Drawing Numbers**

Sales Drawing

SD-38700-002

This document was generated on 10/13/2014

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**