

# RegloCard-Plus / Combifront / InterCard

## Enclosure with Pg pre-punchings in the terminal compartment



RCP 1300

Order no.: 41130109

Pre-punchings: 1 x Pg 9, 1 x Pg 11, 1 x Pg 13,5

\* = Available on request.

### Characteristics

Colour of enclosure group

Light grey

Protection class

IP 65

Enclosure Material

ABS, PC; seal made of EPDM; UL 94 V0 types on request; for details see Technical Information

Scope of delivery

Base, crystal-clear lid, hinged, mounted with snap lock, terminal compartment lid, catch, blind plug, screws

Note

CSA certificate for all V0 versions on request.


Enclosures without pre-punchings on request.

### Dimensions

Dimensions

131 x 186 x 103 mm

Product drawing

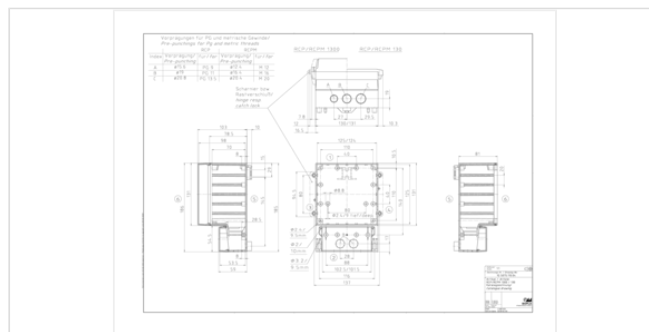

### Important!

To compensate for pressure when temperatures change and cause moisture in the enclosure, we recommend that you use a pressure compensation element.

» Additional information

### Technical documentation / Downloads

## Technical drawings

3D product data in STEP format: Registration necessary

Product drawing in PDF format: 41130109 RCP-1300.pdf (98.5 KB)

Product drawing in DXF format: 41130109 RCP-1300.dxf (827.7 KB)

Drawing for mechanical processing: 41130109 RCP-1300-G.dxf (892.9 KB)

Milling contours are shown here as a DXF file. (Sub D, USB, HDMI, cable glands, ...)

## Product information

Reglocard Plus Combifront Intercard GB.pdf (483.5 KB)

## Matching accessories

---



Cylinder lock / hand knob for retro-fitting in the snap-lock mechanism

41002501 RCP/RCPM - HK Hand knob



Wall brackets, screw-on at rear

41000309 RCP/RCPM - WL



Mounting panels, laminated paper

41000350 RCP/RCPM 130 M For RCP(M) 130(0) Brown



Front panels, natural-coloured anodised aluminium

27000100 FAE 130 For RCP(M) 130(0), 1mm



Cylinder catch for CC 500 TK / NGTK

21008310 SHLO-302 Cylinder lock



Screws (SHR) and distance bolts (DIBLZ) for mounting bosses in plastic enclosures

59006190 SHR Z KA25x6 SD = 2,5 / ND = 2,0 / KD = 4,4  
59006217 SHR Z KA30x8 SD = 3,0 / ND = 2,4-2,6 / KD = 6,0