


Ring Terminals



SPECIFICATION:

Material	Copper
Surface material	Tin-plated
Insulation material	Vinyl
Max. temperature	+105 °C
Voltage Rating	600 V

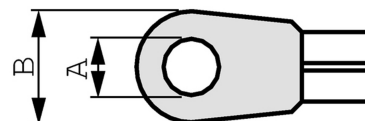

PRODUCT RANGE:

Article Nr.	Cross-section	AWG	Colour	A	B	Length	Thickness	Stud Size
RND 465-00624	0.5...1.5 mm ²	22-16 AWG	Red	3.2 mm	5.5 mm	18.5 mm	0.75 mm	#4
RND 465-00625	0.5...1.5 mm ²	22-16 AWG	Red	4.3 mm	6.6 mm	21.4 mm	0.75 mm	#8
RND 465-00626	0.5...1.5 mm ²	22-16 AWG	Red	5.3 mm	8 mm	22.7 mm	0.75 mm	#10
RND 465-00627	0.5...1.5 mm ²	22-16 AWG	Red	6.4 mm	11.6 mm	28.6 mm	0.75 mm	1/4
RND 465-00628	0.5...1.5 mm ²	22-16 AWG	Red	8.4 mm	11.6 mm	28.6 mm	0.75 mm	5/16
RND 465-00629	1.5...2.5 mm ²	16-14 AWG	Blue	3.2 mm	6.6 mm	21.5 mm	0.8 mm	#4
RND 465-00630	1.5...2.5 mm ²	16-14 AWG	Blue	4.3 mm	6.6 mm	21.3 mm	0.8 mm	#8
RND 465-00631	1.5...2.5 mm ²	16-14 AWG	Blue	5.3 mm	8.5 mm	23.5 mm	0.8 mm	#10
RND 465-00632	1.5...2.5 mm ²	16-14 AWG	Blue	6.4 mm	12 mm	28.6 mm	0.8 mm	1/4
RND 465-00633	1.5...2.5 mm ²	16-14 AWG	Blue	8.4 mm	12 mm	28.6 mm	0.8 mm	5/16
RND 465-00634	1.5...2.5 mm ²	16-14 AWG	Blue	10.5 mm	13.7 mm	32.4 mm	0.8 mm	3/8
RND 465-00635	4...6 mm ²	12-10 AWG	Yellow	5.3 mm	9.5 mm	28 mm	1 mm	#10
RND 465-00636	4...6 mm ²	12-10 AWG	Yellow	6.4 mm	12 mm	34 mm	1 mm	1/4
RND 465-00637	4...6 mm ²	12-10 AWG	Yellow	8.4 mm	15 mm	36.5 mm	1 mm	5/16
RND 465-00638	4...6 mm ²	12-10 AWG	Yellow	10.5 mm	15 mm	36.5 mm	1 mm	3/8
RND 465-00680	4...6 mm ²	12-10 AWG	Yellow	4.3 mm	7.4 mm	27.3 mm	1 mm	