


E40525



Process adapters aseptic flange DIN11864-2A

ADAPT DIN11864-2A DN80

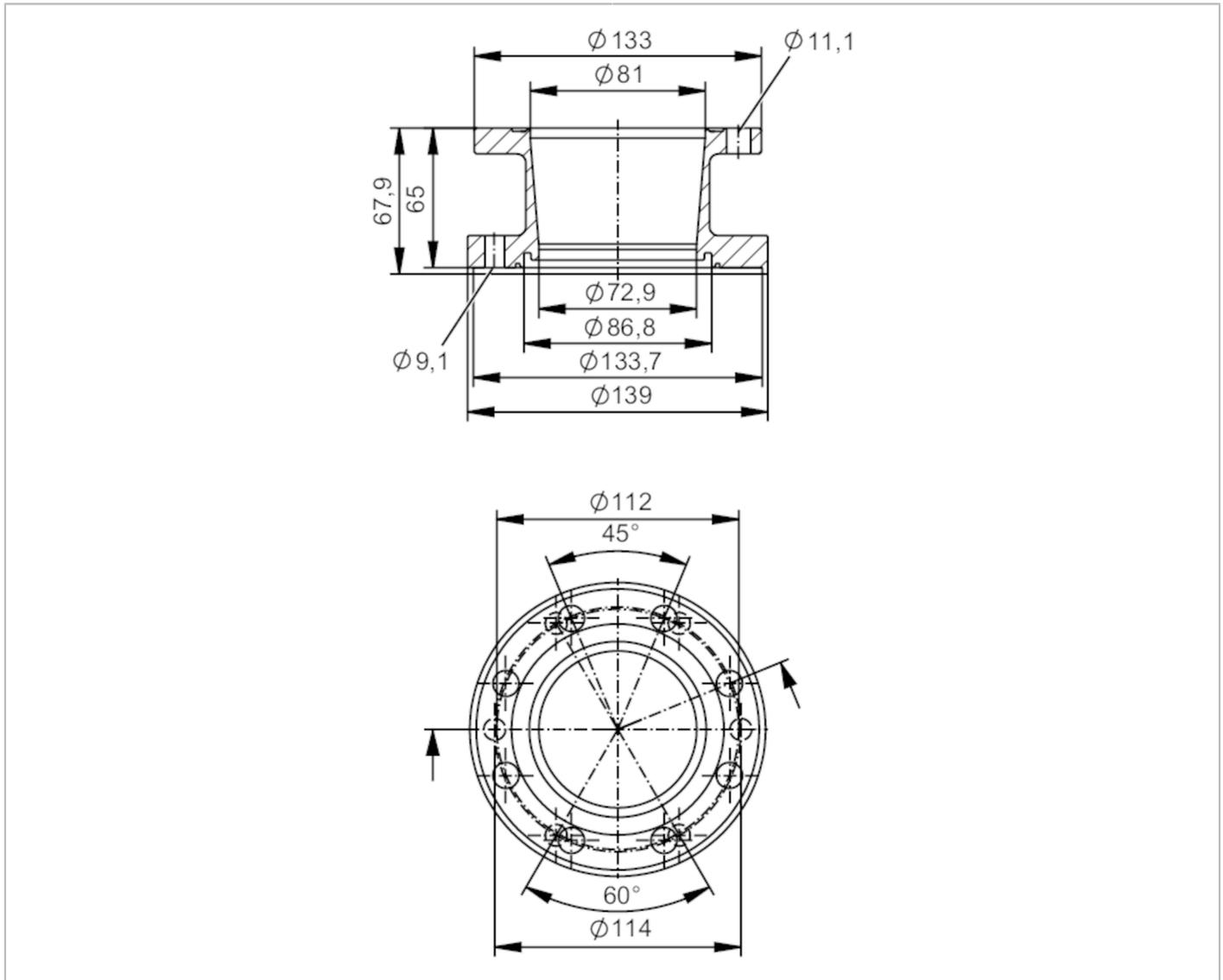

Application	
Design	for volumetric flow meters SMF
Application	food and beverage industry; hygienic systems
Pressure rating	25 bar 2.5 MPa
Tests / approvals	
Pressure Equipment Directive	A possible classification to PED depends on the application and has to be carried out by the user / operator.
Safety instructions	The compatibility between medium and product material has to be checked in all applications.
Mechanical data	
Weight [g]	5730.8
Materials	stainless steel (316L/1.4404)
Nominal diameter	DN80 (3")
Sensor connection	ifm-specific device flange

E40525



Process adapters aseptic flange DIN11864-2A

ADAPT DIN11864-2A DN80

Process connection	aseptic flange DIN 11864-2A
Process connection suitable for pipe standard	(DIN EN 10357 series A); (DIN 11866 series A); (DIN 11850 series 2)
Surface characteristics Ra/Rz of the wetted parts	Ra ≤ 0.4 μm
Accessories	
Items supplied	screws 12
Remarks	
Pack quantity	2 pcs.