


554248 ADNGF-40-5-P-A Compact cylinder - Series from 05-2023

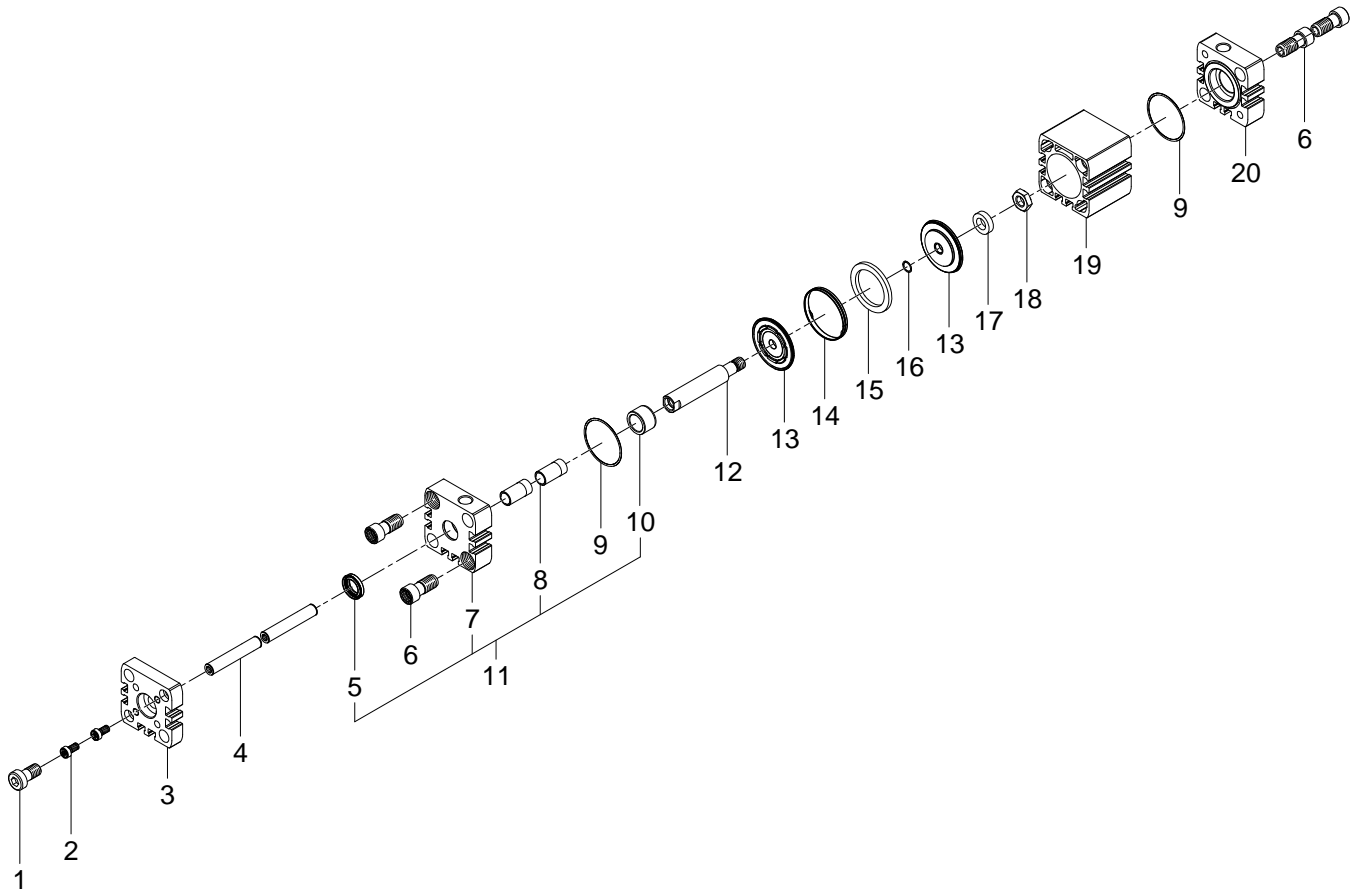

554248 ADNGF-40-5-P-A Compact cylinder - Series from 05-2023

Pos.	Part no.	Type	Note	Qty.	Unit
A	673624	ADN-40-P-A Set of wearing parts	Spare parts: 5, 9, 13, 14, 16	1	PC
1	371539	DIN 6912-M8X16-8.8 Socket head screw	Tightening torque 10 Nm / 7.4 lbf ft Use locking compound 8181258 CYBERBOND TI 7680	1	PC
2	207729	DIN 7984-M5X10-8.8 Socket head screw	Tightening torque 3.7 Nm / 2.7 lbf ft Use locking compound 8181258 CYBERBOND TI 7680	2	PC
3	8154751	ADNGF-40 Moment compensator		1	PC
4	8154755	ADNGF-40-X- Guide rod		2	PC
5	359749	WIFC1-12X16,5X4-TPE-U Wiper seal	Lubricate with 684474 LUB-KC1 during assembly	1	PC
6	658856	ADN-32/40 flange screw	Tightening torque 27 Nm / 19.9 lbf ft Use locking compound 8181258 CYBERBOND TI 7680	4	PC
7		ADNGF-40 Bearing cap	Not available separately, see position 11	1	PC
8		PSM-0810-13 Plain bearing	Not available separately, see position 11	2	PC
9		B-40X1,2-N-NBR75 O-ring ISO3601	Lubricate with 684474 LUB-KC1 during assembly Not available separately, see position A	2	PC
10		ADN-32/40 Bearing	Not available separately, see position 11	1	PC
11	8151256	ADNGF-40 Bearing cap module		1	PC
12	683596	ADN-40- - Piston rod	When ordering please specify the configuration (see type plate)	1	PC
13		BA-K01D-040 Piston module	Not available separately, see position A	2	PC
14		BA-K01F-040 Guiding band	Not available separately, see position A	1	PC
15	675529	36,9X30,4X4BA-K01M-040LP Ring magnet		1	PC
16		B-9,5X1,5-N-NBR70 O-ring ISO3601	Not available separately, see position A	1	PC
17	356369	11 X 16 X 4 Ring		1	PC
18	211437	DIN 439-B-M10X1,25-04 Hex nut	Tightening torque 13.5 Nm / 10.0 lbf ft Use locking compound 8181258 CYBERBOND TI 7680	1	PC
19		ADN-40-X- Cylinder barrel	Lubricate with 684474 LUB-KC1 during assembly Not available	1	PC
20	1305963	ADN-40 End cap		1	PC