


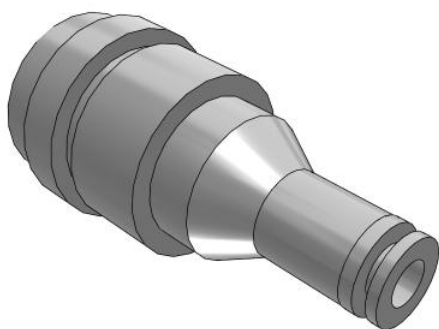




KK*S-*H, S-Couplers, Straight Type with One-touch Fitting KK4S-06H

Datasheet

- Straight Type with One-touch Fitting.
- Body size: M5, 1/8, 1/4, 1/2.
- Applicable Tubing O.D.: Ø3.2, Ø4, Ø6, Ø8, Ø10, Ø12, Ø16.

Standard specifications

Body Size	4 (1/4)
Applicable Tubing O.D.	Ø6 mm
Pressure medium	Air, Water
Maximum operating pressure	1.0 MPa
Minimum operating pressure	0 kPa
Proof pressure	1.5 MPa
Maximum ambient temperature	60 °C / 40 °C for Water
Minimum ambient temperature	-5 °C (with no freezing) / 5 °C for Water
Effective Area	39 mm ²
Sealing principle	Electroless nickel plated (copper-free application), With male thread sealant
Weight	0.048 Kg

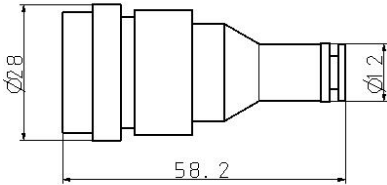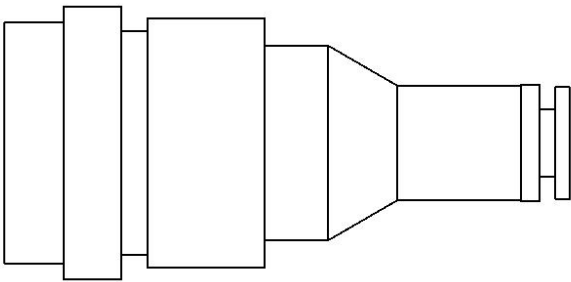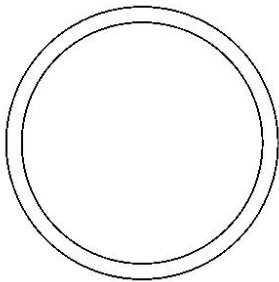

Specifications are subject to change without prior notice and any obligation on the part of the manufacturer.

Additional information

Catalogue

[KK-C_EU.pdf](#)