


Datasheet

Stock No: 297-1184

RS PRO IP44 inspection window, 49x27x78mm

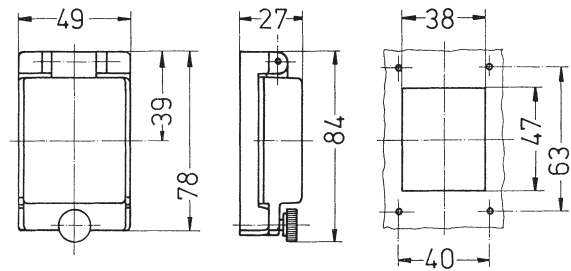

Product Details

Inspection Windows

IP67 (The 2 Module window has IP rating 44)

Polycarbonate inspection windows in smoked grey for 2, 6, 8 and 12 modules. Available with or without break break-away finger protection panel, suitable for DIN 43880//46277-3 cases

Windows are spring-loaded and can be secured with thumb screws

Temperature rating -25°C to +80°C

Specifications:

Type	Inspection Window
Length	49mm
Width	27mm
Height	78mm
Dimensions	49 x 27 x 78mm
Material	PC
For Use With	DIN 43880, 46277-3
Colour	Grey