



#### General characteristics

|                          |               |
|--------------------------|---------------|
| Colour                   | Grey          |
| IEC degree of protection | IP66 and IP67 |

#### Mechanical features

|        |   |     |
|--------|---|-----|
| Weight | g | 570 |
|--------|---|-----|

#### UL technical data

|                         |         |
|-------------------------|---------|
| UL degree of protection | NEMA 4X |
|-------------------------|---------|

#### Ambient conditions

Temperature


Operating temperature

|     |    |     |
|-----|----|-----|
| min | °C | -25 |
| max | °C | +70 |

Storage temperature

|     |    |     |
|-----|----|-----|
| min | °C | -40 |
| max | °C | +85 |

#### Dimensions

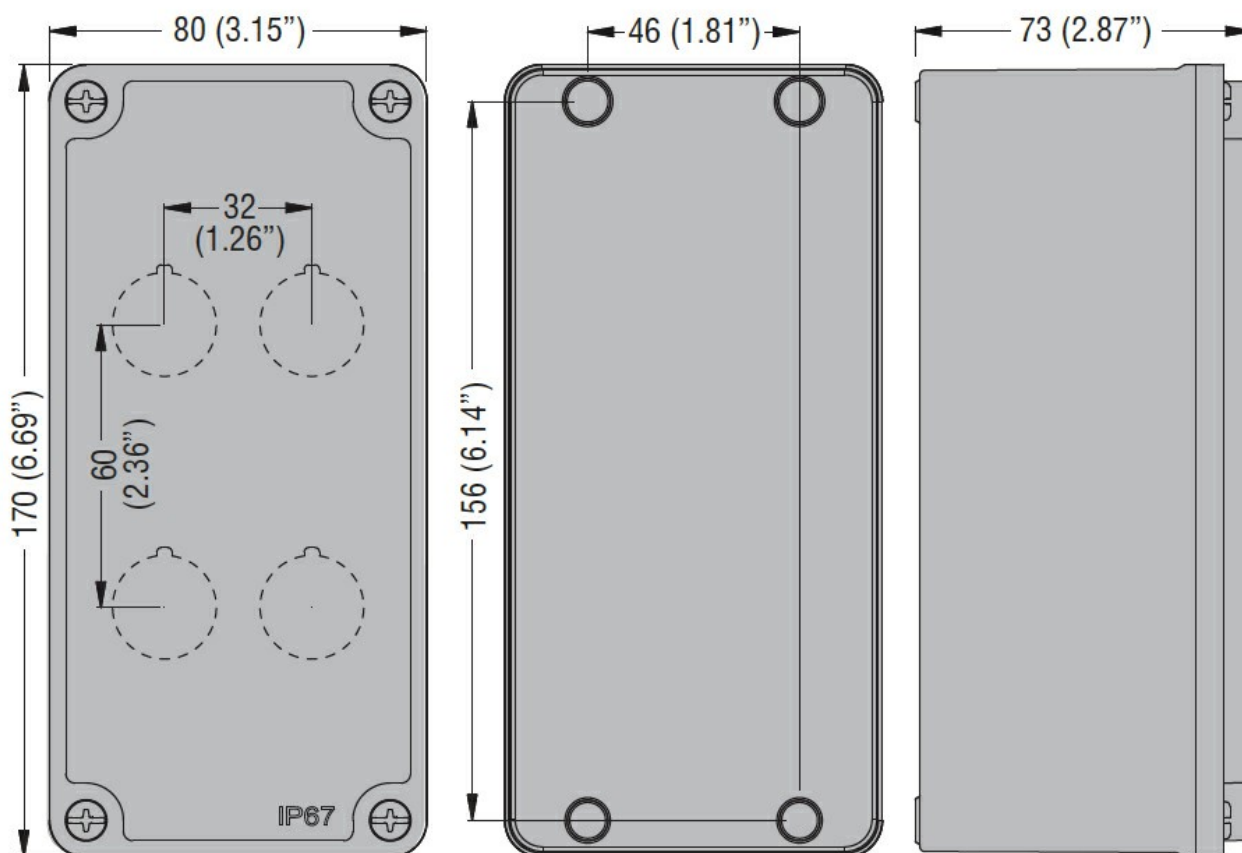

#### Certifications and compliance

Compliance

IEC/EN 60947-5-1

---

Certificates

cULus  
EAC

---

ETIM classification

ETIM 8.0

EC000200 -  
Enclosure for  
control circuit  
devices