

Datasheet

5Vpp 80dB PCB Mount Piezo Transducer

RS Stock number [511-7670](#)




Specifications:

Rated Voltage (Vp-p square wave):	5Vp-p
Operating Voltage:	1-20Vp-p
Rated Current at Rated Voltage:	1mA
Capacitance:	13000±300%pF
Sound Output at 4000Hz at 10cm	≥80dB
Resonant Frequency	4000±500Hz
Operating Temperature:	-20°C to +70°C
Storage Temperature:	-30°C to +80°C
Weight:	1g
Drive Type:	External
Mounting Type:	Through Hole
Tone Type:	Continuous

This product requires additional electronic circuitry to operate as a sounder.

Dimensions:

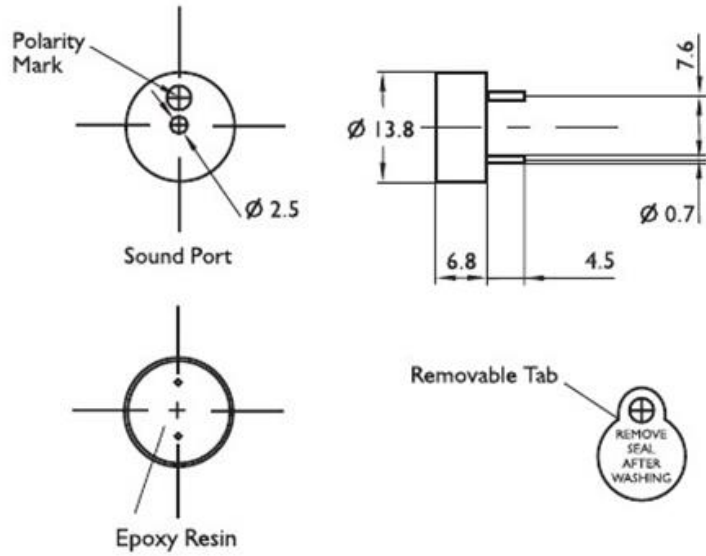

Dimensions Unit: mm

Tolerance: $\pm 0.5\text{mm}$