

## ToLEDo GLS

ToLEDo GLS 6.5W 470LM 827 E27 SL

0026386



### Range features

- Long life of up to 30,000 hours; up to 30 times longer than incandescent lamps
- Over 80% energy saving compared to incandescent - Rapid payback on investment
- Homelight 2700K colour temperature - ideal for domestic lighting, restaurants, leisure and hotels
- Instant start - ideal for use on presence detection and in high use areas



### PRODUCT OVERVIEW

Light colour	Homelight
Technology	LED
Ordering number	0026386
Average life (Rated) (h)	15000
Energy class	A+
Lamp shape	A60
Lamp finish	Frosted
Dimmable	No
Cap/Base	E27
Type	ToLEDo GLS
EAN code	5410288263861
CRI (Ra)	80
Colour temperature (K)	2700
Luminous flux (Rated) (lm)	470
Watt (Nominal) (W)	6.5
Equivalent watt (W)	40
Voltage (V)	220-240

# ToLEDo GLS

ToLEDo GLS 6.5W 470LM 827 E27 SL

**0026386**

## DATA TABLE

### General data

<b>Dry applications use only</b>	Yes
<b>Ordering number</b>	0026386
<b>Technology</b>	LED
<b>Energy saving lamp</b>	Yes
<b>Average life (Nominal) (h)</b>	15000
<b>Average life (Rated) (h)</b>	15000
<b>Energy class</b>	A+
<b>Lamp finish</b>	Frosted
<b>Lamp shape</b>	A60
<b>Dimmable</b>	No
<b>Cap/Base</b>	E27
<b>Type</b>	ToLEDo GLS
<b>EAN code</b>	5410288263861
<b>Long description</b>	Long life of up to 30,000 hours; up to 30 times longer than incandescent lamps. Over 80% energy saving compared to incandescent - Rapid payback on investment. Homelight 2700K colour temperature - ideal for domestic lighting, restaurants, leisure and hotels. Instant start - ideal for use on presence detection and in high use areas
<b>Product name</b>	ToLEDo GLS 6.5W 470LM 827 E27 SL
<b>Lamp mercury content (mg)</b>	0
<b>Starting time (max) (s)</b>	0.05
<b>Warm-up time to 60% of full light (max) (s)</b>	< 1s => 60%
<b>Control gear required</b>	No
<b>Intended purpose</b>	No
<b>No. of switching cycles before premature failure (min)</b>	20,000
<b>Special purpose lamp</b>	No
<b>Sales pack quantity</b>	6
<b>Optimal operating condition (°C)</b>	25

### Optical data

<b>Light colour</b>	Homelight
<b>CRI (Ra)</b>	80
<b>Colour temperature (K)</b>	2700
<b>Luminous flux (Rated) (lm)</b>	470
<b>Lumen maintenance at end of nominal life (%)</b>	70
<b>Luminous flux (Nominal) (lm)</b>	470

## ToLEDo GLS

ToLEDo GLS 6.5W 470LM 827 E27 SL

**0026386**

### Electrical data

<b>kWh per 1000 hours burning time</b>	7
<b>Watt (Rated) (W)</b>	6.5
<b>Watt (Nominal) (W)</b>	6.5
<b>Equivalent watt (W)</b>	40
<b>Voltage (V)</b>	220-240
<b>Lamp power factor</b>	0.7

### Physical data


<b>Weight (kg)</b>	0.09
<b>Lamp Length (mm) - C/L</b>	110
<b>Max. Lamp Diameter (mm) - D</b>	60
<b>Single packaging type</b>	Box/Sleeve
<b>Single package dimensions (L x W x H) (cm)</b>	11.40 x 6.40 x 6.40
<b>Inner package dimensions (L x W x H) (cm)</b>	20.90 x 14.10 x 14.10
<b>Inner package net weight (kg)</b>	0.52
<b>Outer package dimensions (L x W x H) (cm)</b>	74.80 x 21.70 x 31.80

## ToLEDo GLS

ToLEDo GLS 6.5W 470LM 827 E27 SL

0026386

### TECHNICAL DRAWINGS

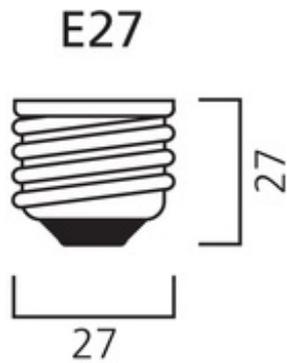

### ENERGY LABEL

