


Panel-mount socket SLB4-G-...

Insulated, rigid, Ø 4 mm, accepting spring-loaded Ø 4 mm plugs with rigid insulating sleeve. Machined brass. The socket

is screwed into pre-drilled panels of plastic, metal, etc.

Connection: Threaded bolt M4 and soldering hole

SLB4-G

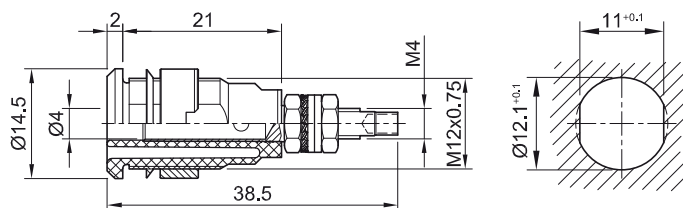

Order No.	Type	Rated voltage/current		*Standard colors										
23.3020-*	SLB4-G	1000 V, CAT III / 32 A 600 V, CAT IV / 32 A		<table border="1"> <tr><td>20</td><td>21</td><td>22</td><td>23</td><td>24</td></tr> <tr><td>25</td><td>26</td><td>27</td><td>28</td><td>29</td></tr> </table>	20	21	22	23	24	25	26	27	28	29
20	21	22	23	24										
25	26	27	28	29										
49.7043-*	SLB4-G/N-X	1000 V, CAT III / 32 A 600 V, CAT IV / 32 A		<table border="1"> <tr><td>20</td><td>21</td><td>22</td><td>23</td><td>24</td></tr> <tr><td>25</td><td>26</td><td>27</td><td>28</td><td>29</td></tr> </table>	20	21	22	23	24	25	26	27	28	29
20	21	22	23	24										
25	26	27	28	29										

Component parts

23.7111-*	BI-SLB4-G	Socket SLB4-G without nut		
49.7034-*	BI-SLB4-G/N	Socket SLB4-G/N-X without nut		
23.5120	MUR/M12x0,75	Round nut, suitable for	SLB4-G, SLB4-G/N-X	Page 149
23.5108	SSP4	Washer, suitable for	SLB4-G	Page 149
22.6509	MU0,8D/M4	2 hexagon nuts, suitable for	SLB4-G	Page 148
22.6539	MU0,8D/M4N	2 hexagon nuts, suitable for	SLB4-G/N-X	Page 148
22.6511	U/M4	Washers, suitable for	SLB4-G	Page 149
22.6533	FS/M4	Spring washer, suitable for	SLB4-G	Page 150



Tube spanners SS2, SS425, page 152



Assembly instructions MA165

www.staubli.com/electrical