


LabelWriter™ 450

DYMO®

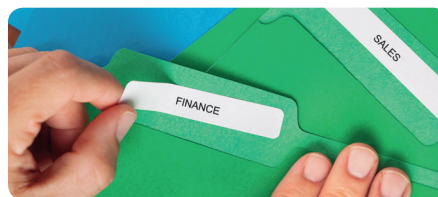

Professional Label Printer for PC and Mac®

- No expensive ink or toner needed - uses thermal printing technology
- Customize and print address, shipping, file folder and barcode labels, plus name badges and more with DYMO® Label™ v.8 software—all from your PC or Mac®*
- Save time – create labels directly from text in Microsoft® Word, Excel®, Outlook®, QuickBooks® and other programs or easily print addresses from Outlook® Contacts or Mac® Address Book
- Eliminate the waste and hassles of sheet labels — print precise quantities of labels
- Prints crystal-clear barcodes, labels and graphics with 600 x 300 dpi resolution
- Conserve power with “sleep mode”
- Create custom labels from 60+ label styles and layouts



LABELS



labels/min.*

* Compatible with Windows Vista®, Windows® 7, Windows® 8, Mac OS® X 10.5 or later – Intel® only

Single Unit Includes:

- LabelWriter 450 Label Printer
- Address Labels Starter Roll
- Adapter
- Power Cable
- USB Cable
- Quick Start Guide – PC and Mac®
- Cleaning Card
- DYMO® Label™ v.8 Software Installation CD



Quick Specs

Unit Dimensions (L x W x H)	127 x 187 x 134mm
Weight	1.3 kg
Mac®/PC Compatible	Yes
Max Label Width	58.42mm
Resolution	600 x 300 dpi
Printing System	Direct Thermal
Print Speed	51 labels/minute*
Barcodes	Yes
Power Source	Adapter Power Cable
Networking	Print Server Sold Separately
Country of Origin	China

*4-line address label

Item Number	Description		Length (cm)	Width (cm)	Height (cm)	Weight (kg)	QTY	EAN	Customer Price
S0838810	LabelWriter 450 ENG-UK/HK	Unit	14.0	27.0	16.3	1.6	1	3501170838815	
		Shelf	-	-	-	-	-	-	
		Case	43.0	27.8	35.0	-	6	13501170838812	
		Pallet	120.0	80.0	120.0	-	108	-	
Accessories									
925106	USB Cable	Unit	-	-	-	-	-	-	
923772	Power Cable	Unit	-	-	-	-	-	-	
922983	Cleaning Card	Unit	-	-	-	-	-	-	
931160	Switching Adapter	Unit	29.7	24.2	16.3	0.5	-	-	
S0787940	Spool 450 series	Unit	-	-	-	-	-	-	

dymo.com



Print one label or hundreds – without the waste and hassles of sheet labels.

Label Type	Description	Code #	Size in mm	Labels/Roll	Rolls/Box	Adhesive	Material
Mailing	Standard Address Labels	S0722370	28 x 89	130	2	Permanent	Paper
	Standard Address Labels	S0722360	28 x 89	130	24	Permanent	Paper
	Assorted Colour labels	S0722380	28 x 89	130	2	Permanent	Paper
	Large Address Labels	S0722400	36 x 89	260	2	Permanent	Paper
	Large Address Labels	S0722390	36 x 89	260	24	Permanent	Paper
	Large Address Labels	S0722410	36 x 89	260	1	Permanent	Transparent Plastic
	Large Return Address Label	S0722520	25 x 54	500	1	Permanent	Paper
Shipping	Shipping / Name badge Labels	S0722430	54 x 101	220	1	Permanent	Paper
	Shipping / Name badge Labels	S0722420	54 x 101	220	12	Permanent	Paper
Multit-Purpose	Multi-Purpose Labels	S0722530	13 x 25	1000	1	Removable	Paper
	Square Multi-Purpose Labels	S0929120	25 x 25	750	1	Removable	Paper
	Multi-Purpose Labels	S0722550	19 x 51	500	1	Removable	Paper
	Multi-Purpose Labels	S0722540	57 x 32	1000	1	Removable	Paper
	Large Multi-Purpose Labels	S0722440	54 x 70	320	1	Permanent	Paper
Specialty	Suspension file labels	S0722460	12 x 50	220	1	Permanent	Paper
	LAF Labels small	S0722470	38 x 190	110	1	Permanent	Paper
	LAF Labels large	S0722480	59 x 190	110	1	Permanent	Paper
	Small name badge label	S0722560	41 x 89	300	1	Removable	Paper
	Appointment / name badge cards	S0929100	51 x 89	300	1	Non-adhesive	Paper
	Large name badge cards	S0929110	62 x 106	250	1	Non-adhesive	Paper
	CD Labels	S0719250	57 diameter	160	1	Permanent	Paper

Country of Origin: Belgium

DISTRIBUTED BY:
Newell Europe Sàrl
Chemin de Blandonnet 10
1214 Vernier – Switzerland
WWW.DYMO.COM



A **Newell Rubbermaid** Brand

This information is being provided for general information purposes and the compliance standards and certifications referenced herein are based on current standards which are subject to change.

©2014 Newell Europe LLC

A NewellRubbermaid Company™	SCHAWK! RMZ Milenia Business Park Campus - 2, 20th Floor No. 145, Dr.M. G. R. Road Hundrichowah (Chennai 600 036 India) T +91 44 4253 7777 www.schawk.com	 CYAN MAGENTA YELLOW BLACK	
	Use the PANTONE MATCHING SYSTEM for accurate color reproduction		
	VERSION	JOB DESCRIPTION : NRM_EU_Writing_Dymo_1362812_EMEA Product Handbooks_UK Masters FILE NAME : DY_1362812_2014_EMEA_LW450_TechSheet_v7.indd	BRAND : WRITING-DYMO
	7 DATE : 10-01-2014 OPERATOR : MKS	SCHAWK JOB # : 310253D NRM JOB # : 1362812 COMPONENT # : N/A	CATEGORY OF WORK : COLLATERALS-FACT BOOKS NO. OF PAGES# : 2 PAGES SIZE : A4
	NOTE :		