

# Stainless Steel Free-Standing Type I2 Enclosures Accessory Selection Guide

## Type I2 Free-Standing Enclosures Accessory Selection

(See Accessories for Details)

### Panels

#### Catalog Number

Steel	Conductive	Description	Panel Size in. (mm)
A60P24F1	A60P24F1G	Full Panel	48.00 x 20.00 (1219 x 508)
A60P24F2	A60P24F2G	Half Panel	24.88 x 20.00 (632 x 508)
A72P24F1	A72P24F1G	Full Panel	60.00 x 20.00 (1524 x 508)
A72P24F2	A72P24F2G	Half Panel	30.88 x 20.00 (784 x 508)
A90P24F1	A90P24F1G	Full Panel	78.00 x 20.00 (1981 x 508)
A90P24F2	A90P24F2G	Half Panel	39.00 x 20.00 (1013 x 508)
A72P30F1	A72P30F1G	Full Panel	60.00 x 26.00 (1524 x 660)
A72P30F2	A72P30F2G	Half Panel	30.88 x 26.00 (784 x 660)
A60P36F1	A60P36F1G	Full Panel	48.00 x 32.00 (1219 x 813)
A60P36F2	A60P36F2G	Half Panel	24.88 x 32.00 (632 x 813)
A72P36F1	A72P36F1G	Full Panel	60.00 x 32.00 (1524 x 813)
A72P36F2	A72P36F2G	Half Panel	30.88 x 32.00 (784 x 813)
A90P36F1	A90P36F1G	Full Panel	78.00 x 32.00 (1981 x 813)
A90P36F2	A90P36F2G	Half Panel	39.88 x 32.00 (1013 x 813)

Two-Door Single-Access Enclosures											
A604818SSFSD	A724818SSFSD	A726018SSFSD	A727218SSFSD	A904820SSFSD	A907220SSFSD	A724824SSFSD	A726024SSFSD	A727224SSFSD	A907224SSFSD	A726036SSFSD	A907236SSFSD
• <sup>b</sup>	• <sup>a,b</sup>			• <sup>a,b</sup>		• <sup>a,b</sup>					
• <sup>b</sup>	• <sup>a,b</sup>			• <sup>a,b</sup>		• <sup>a,b</sup>					
	• <sup>b</sup>			• <sup>a,b</sup>		• <sup>b</sup>					
• <sup>a,b</sup>	• <sup>b</sup>			• <sup>a,b</sup>		• <sup>b</sup>					
• <sup>a,b</sup>	• <sup>a,b</sup>			• <sup>b</sup>		• <sup>a,b</sup>					
		• <sup>b</sup>					• <sup>b</sup>				• <sup>b</sup>
		• <sup>b</sup>					• <sup>b</sup>				• <sup>b</sup>
			• <sup>a,b</sup>		• <sup>a,b</sup>			• <sup>a,b</sup>	• <sup>a,b</sup>		• <sup>a,b</sup>
			• <sup>a,b</sup>		• <sup>a,b</sup>			• <sup>a,b</sup>	• <sup>a,b</sup>		• <sup>a,b</sup>
			• <sup>b</sup>		• <sup>a,b</sup>			• <sup>b</sup>	• <sup>a,b</sup>		• <sup>a,b</sup>
			• <sup>b</sup>		• <sup>a,b</sup>			• <sup>b</sup>	• <sup>a,b</sup>		• <sup>a,b</sup>
				• <sup>b</sup>				• <sup>b</sup>	• <sup>b</sup>		• <sup>b</sup>
			• <sup>a,b</sup>		• <sup>b</sup>			• <sup>a,b</sup>	• <sup>b</sup>		• <sup>b</sup>

### Swing-Out Panels

Catalog Number	Description	Panel Size in. (mm)
A72SP24F3	Full Panel	60.00 x 18.81 (1524 x 478)
A72SP24F4	Half Panel <sup>c</sup>	30.88 x 18.81 (784 x 478)
A72SP30F3	Full Panel	60.00 x 24.81 (1524 x 630)
A72SP30F4	Half Panel <sup>c</sup>	30.88 x 24.81 (784 x 630)
A72SP36F3	Full Panel	60.00 x 30.81 (1524 x 783)
A72SP36F4	Half Panel <sup>c</sup>	30.88 x 30.81 (784 x 783)
A90SP36F3	Full Panel	78.00 x 30.81 (1981 x 783)
A90SP36F4	Half Panel <sup>c</sup>	39.88 x 30.81 (1013 x 783)

	• <sup>b</sup>					• <sup>b</sup>					
	• <sup>b</sup>					• <sup>b</sup>					
		• <sup>b</sup>					• <sup>b</sup>			• <sup>b</sup>	
		• <sup>b</sup>					• <sup>b</sup>			• <sup>b</sup>	
			• <sup>b</sup>					• <sup>b</sup>			
			• <sup>b</sup>					• <sup>b</sup>			
						• <sup>b</sup>			• <sup>b</sup>		• <sup>b</sup>
						• <sup>b</sup>			• <sup>b</sup>		• <sup>b</sup>

### Side-Mounted Panels

Catalog Number	Steel	Conductive	Description	Panel Size in. (mm)
A60SMP14	A60SMP14	A60SMP14G	14-in. Wide Panel (356 mm)	48.00 x 14.00 (1219 x 356)
A72SMP14	A72SMP14	A72SMP14G	14-in. Wide Panel (356 mm)	60.00 x 14.00 (1524 x 356)
A90SMP14	A90SMP14	A90SMP14G	14-in. Wide Panel (356 mm)	78.00 x 14.00 (1981 x 356)
A72SMP20	A72SMP20	A72SMP20G	20-in. Wide Panel (508 mm)	60.00 x 20.00 (1524 x 508)
A90SMP20	A90SMP20	A90SMP20G	20-in. Wide Panel (508 mm)	78.00 x 20.00 (1981 x 508)

• <sup>d</sup>											
	• <sup>d</sup>	• <sup>d</sup>	• <sup>d</sup>			•	•	•		•	
					•	•			•		•
						• <sup>d</sup>	• <sup>d</sup>	• <sup>d</sup>		•	
									• <sup>d</sup>		•

<sup>a</sup>Requires heavy duty panel supports


<sup>b</sup>Requires center panel supports

<sup>c</sup>Fits in top half or bottom half of enclosure


<sup>d</sup>Will not fit if other panels are also installed in same enclosure

# Stainless Steel Free-Standing Type 12 Enclosures Accessory Selection Guide

## Free-Standing Enclosure Group Accessory Selection Guide

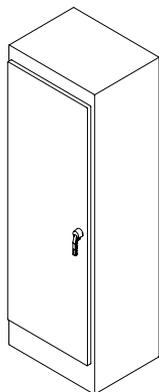

**Stainless Steel  
Free-Standing Type 4X  
Single-Door Enclosures**

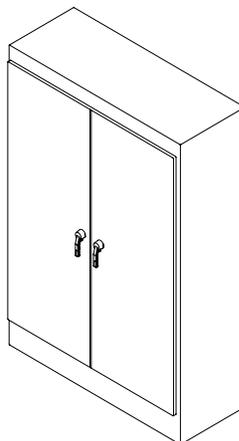


**Stainless Steel  
Free-Standing Type 4X  
Two-Door Enclosures**


87795187

### Internal Accessories


*(See Accessories for Details)*

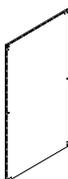

Panel for  
Single-Door  
Enclosures

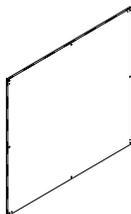

Panel for  
Two-Door  
Enclosures

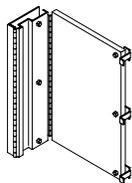

Swing-Out  
Panel



Side-Mounted  
Panel



Heavy Duty  
Panel Supports




Center Panel  
Support



Rack Mounting  
Angles for 19-  
and 24-inch  
Equipment




Clip Nut Package

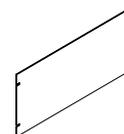


Rack Panels for  
19- and 24-inch  
Equipment



Screw Package

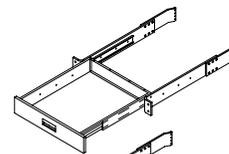

12-Inch Rack  
Mounted Drawer

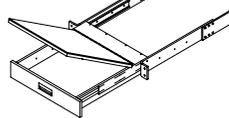

Writing Surface  
for Drawers



14-inch Rack  
Mounted Shelf



Guides for Rack  
Mounted  
Equipment

C2586-C

To select an accessory for an enclosure, see the following Free-Standing Enclosure Accessory tables.

# Stainless Steel Free-Standing Type I2 Enclosures Accessory Selection Guide

## Type I2 Free-Standing Enclosures Accessory Selection

(See Accessories for Details)

Two-Door Single-Access Enclosures											
A604818SSFSFD	A724818SSFSFD	A726018SSFSFD	A727218SSFSFD	A904820SSFSFD	A907220SSFSFD	A724824SSFSFD	A726024SSFSFD	A727224SSFSFD	A907224SSFSFD	A726036SSFSFD	A907236SSFSFD
• <sup>b</sup>	• <sup>b</sup>	• <sup>b</sup>	• <sup>b</sup>			• <sup>b</sup>	• <sup>b</sup>	• <sup>b</sup>		• <sup>b</sup>	
				• <sup>b</sup>	• <sup>b</sup>				• <sup>b</sup>		• <sup>b</sup>

### Heavy Duty Panel Supports

Catalog Number	Description	Panel Size in. (mm)
A60FSDPS	2 Full-Length	57.25 (1454)
A72FSDPS	Panel	69.25 (1759)
A90FSDPS	Supports	87.25 (2216)

### Panels

Catalog Number	Steel	Conductive	Description	Panel Size in. (mm)	A604818SSFSFD	A724818SSFSFD	A726018SSFSFD	A727218SSFSFD	A904820SSFSFD	A907220SSFSFD	A724824SSFSFD	A726024SSFSFD	A727224SSFSFD	A907224SSFSFD	A726036SSFSFD	A907236SSFSFD
A60P48F1	A60P48F1G	A60P48F1G	Full Panel	48.00 x 44.00 (1219 x 1118)	•	• <sup>a</sup>			• <sup>a</sup>		• <sup>a</sup>					
A72P48F1	A72P48F1G	A72P48F1G	Full Panel	60.00 x 44.00 (1524 x 1118)		•			• <sup>a</sup>		•					
A72P48F2	A72P48F2G	A72P48F2G	Half Panel	30.88 x 44.00 (784 x 1118)	• <sup>a</sup>	•			• <sup>a</sup>		•					
A90P48F1	A90P48F1G	A90P48F1G	Full Panel	78.00 x 44.00 (1981 x 1118)					•							
A90P48F2	A90P48F2G	A90P48F2G	Half Panel	39.88 x 44.00 (1013 x 1118)		• <sup>a</sup>			•		• <sup>a</sup>					
A72P60F1	A72P60F1G	A72P60F1G	Full Panel	60.00 x 56.00 (1524 x 1422)			•					•			•	
A72P60F2	A72P60F2G	A72P60F2G	Half Panel	30.88 x 56.00 (784 x 1422)			•					•			•	
A72P72F1	A72P72F1G	A72P72F1G	Full Panel	60.00 x 68.00 (1524 x 1727)				•		• <sup>a</sup>		•	• <sup>a</sup>			• <sup>a</sup>
A72P72F2	A72P72F2G	A72P72F2G	Half Panel	30.88 x 68.00 (784 x 1727)				•		• <sup>a</sup>		•	• <sup>a</sup>			• <sup>a</sup>
A90P72F1	A90P72F1G	A90P72F1G	Full Panel	78.00 x 68.00 (1981 x 1727)					•				•			•
A90P72F2	A90P72F2G	A90P72F2G	Half Panel	39.88 x 68.00 (1013 x 1727)			• <sup>a</sup>		•			• <sup>a</sup>	•			•

### Center Panel Supports

Catalog Number	Description	A604818SSFSFD	A724818SSFSFD	A726018SSFSFD	A727218SSFSFD	A904820SSFSFD	A907220SSFSFD	A724824SSFSFD	A726024SSFSFD	A727224SSFSFD	A907224SSFSFD	A726036SSFSFD	A907236SSFSFD
A60FSCPS	Center Panel Support	•											
A72FSCPS	Center Panel Support		•	•	•			•	•			•	•
A90FSCPS	Center Panel Support					•	•				•	•	•

### Clamping Nuts

Catalog Number	Description	A604818SSFSFD	A724818SSFSFD	A726018SSFSFD	A727218SSFSFD	A904820SSFSFD	A907220SSFSFD	A724824SSFSFD	A726024SSFSFD	A727224SSFSFD	A907224SSFSFD	A726036SSFSFD	A907236SSFSFD
APS1420CN	1/4-20 Clamping Nut (Qty. 20) for Special Use	•	•	•	•	•	•	•	•	•	•	•	•
APS51616CN	1/4-18 Clamping Nut (Qty. 20) for Special Use	•	•	•	•	•	•	•	•	•	•	•	•

### Casters

Catalog Number	Description	Size	A604818SSFSFD	A724818SSFSFD	A726018SSFSFD	A727218SSFSFD	A904820SSFSFD	A907220SSFSFD	A724824SSFSFD	A726024SSFSFD	A727224SSFSFD	A907224SSFSFD	A726036SSFSFD	A907236SSFSFD
DMCKC	Set of 4 Casters	4 high x 3 diameter	•	•	•	•	•	•	•	•	•	•	•	•

<sup>a</sup>Requires heavy duty panel supports

<sup>b</sup>Requires center panel supports

<sup>c</sup>Fits in top half or bottom half of enclosure

<sup>d</sup>Will not fit if other panels are also installed in same enclosure

# Stainless Steel Free-Standing Type I2 Enclosures Accessory Selection Guide

## Type I2 Free-Standing Enclosures Rack Mounting Accessory Selection

(See Accessories for Details)

### Rack Mounting Angles L-Style (Type RP) for 19- and 24-in. Equipment

Catalog Number	Description	For Rack Size	No. Units <sup>d</sup>	Angle Length in. (mm)	Two-Door Single-Access Enclosures											
					A604818SSFSFD	A724818SSFSFD	A726018SSFSFD	A727218SSFSFD	A904820SSFSFD	A907220SSFSFD	A724824SSFSFD	A726024SSFSFD	A727224SSFSFD	A907224SSFSFD	A726036SSFSFD	A907236SSFSFD
A60FP24F5	2 Full-Length Angles	19 in. (483 mm)	28	49.00 (1245)	• <sup>b</sup>	• <sup>b</sup>			• <sup>b</sup>		• <sup>b</sup>					
A60FP24F6	2 Half-Length Angles	19 in. (483 mm)	15	26.25 (677)	• <sup>b</sup>											
A72RP24F5	2 Full-Length Angles	19 in. (483 mm)	35	61.25 (1556)		• <sup>b</sup>			• <sup>b</sup>		• <sup>b</sup>					
A72RP24F6	2 Half-Length Angles	19 in. (483 mm)	18	31.50 (800)	• <sup>b</sup>	• <sup>b</sup>					• <sup>b</sup>					
A90RP24F5	2 Full-Length Angles	19 in. (483 mm)	45	78.75 (2000)					• <sup>b</sup>							
A90RP24F6	2 Half-Length Angles	19 in. (483 mm)	23	40.25 (1022)	• <sup>b</sup>	• <sup>b</sup>			• <sup>b</sup>		• <sup>b</sup>					
A72RP30F5	2 Full-Length Angles	24 in. (610 mm)	35	61.25 (1556)			• <sup>b</sup>					• <sup>b</sup>			• <sup>b</sup>	
A72RP30F6	2 Half-Length Angles	24 in. (610 mm)	18	31.50 (800)			• <sup>b</sup>					• <sup>b</sup>			• <sup>b</sup>	

### Rack Mounting Angles U-Style (Type RA) for 19- and 24-in. Equipment

Catalog Number	Description	For Rack Size	No. Units <sup>d</sup>	Angle Length in. (mm)												
A60RA19TH	2 Full-Length Angles	19 in. (483 mm)	28	49.00 (1245)	• <sup>b</sup>	• <sup>b</sup>			• <sup>b</sup>		• <sup>b</sup>					
A72RA19TH	2 Full-Length Angles	19 in. (483 mm)	35	61.25 (1556)		• <sup>b</sup>			• <sup>b</sup>		• <sup>b</sup>					
A90RA19TH	2 Full-Length Angles	19 in. (483 mm)	45	78.75 (2000)					• <sup>b</sup>							
A72RA24TH	2 Full-Length Angles	24 in. (610 mm)	35	61.25 (1556)			• <sup>b</sup>					• <sup>b</sup>			• <sup>b</sup>	

### Clip Nut Package

Catalog Number	Description	Size	Fits													
AN1032	Clip Nut (Pkg of 20)	#10-32 Zinc-Plated	RA Type Mnt Angles	•	•	•	•	•	•	•	•	•	•	•	•	•

### 19-in. Swing-Out Rack Mounting Frames

Catalog Number	Description	For Rack Size	No. Units <sup>d</sup>	Panel Space in. (mm)												
A7230S0F19	Full Swing-Out Frame	19 in. (483 mm)	33	57.88 (1470)			• <sup>b</sup>	• <sup>b</sup>				• <sup>b</sup>	• <sup>b</sup>			• <sup>b</sup>
A7236S0F19	Full Swing-Out Frame	19 in. (483 mm)	33	57.88 (1470)				• <sup>b</sup>				• <sup>b</sup>				
A9036S0F19	Full Swing-Out Frame	19 in. (483 mm)	43	75.36 (1915)					• <sup>b</sup>				• <sup>b</sup>			• <sup>b</sup>

<sup>a</sup>Requires 2 sets U-style (Type RA) rack mounting angles for installation  
<sup>b</sup>Requires center panel support(s) for installation  
<sup>c</sup>Requires swing-out rack mounting frame or rack angles  
<sup>d</sup>1 unit = 1.75 in. (44 mm)



# Stainless Steel Free-Standing Type I2 Enclosures Accessory Selection Guide

## Type I2 Free-Standing Enclosures Rack Mounting Accessory Selection

(See Accessories for Details)

Two-Door Single-Access Enclosures											
A604818SSFSD	A724818SSFSD	A726018SSFSD	A727218SSFSD	A904820SSFSD	A907220SSFSD	A724824SSFSD	A726024SSFSD	A727224SSFSD	A907224SSFSD	A726036FSSSD	A907236FSSSD
						• <sup>a</sup>					
							• <sup>a</sup>			• <sup>a</sup>	

### Writing Surfaces

Catalog Number	Description	Fits Drawer
A19WSDR	Hinged Surface	A19DR2U, A19DR4U
DL29WS	Hinged Surface	DL329DR, DL729DR

### 19- and 24-in. Rack-Mounted Shelves

Catalog Number	Description	For Rack Size	Number of Units <sup>d</sup>	A604818SSFSD	A724818SSFSD	A726018SSFSD	A727218SSFSD	A904820SSFSD	A907220SSFSD	A724824SSFSD	A726024SSFSD	A727224SSFSD	A907224SSFSD	A726036FSSSD	A907236FSSSD
A19SHP6	Pull-Out Shelf	19 in. (483 mm)	2						• <sup>a</sup>						
DL29SHP	Pull-Out Shelf	24 in. (610 mm)	2							• <sup>a</sup>				• <sup>a</sup>	
A19SH6	Fixed Shelf	19 in. (483 mm)	1						• <sup>a</sup>						
DL29SH	Fixed Shelf	24 in. (610 mm)	1							• <sup>a</sup>				• <sup>a</sup>	

### Guides for Rack-Mounted Shelves

Catalog Number	Description	Number of Units <sup>d</sup>	A604818SSFSD	A724818SSFSD	A726018SSFSD	A727218SSFSD	A904820SSFSD	A907220SSFSD	A724824SSFSD	A726024SSFSD	A727224SSFSD	A907224SSFSD	A726036FSSSD	A907236FSSSD
AG1U6	Chassis Guides (2)	1							• <sup>a</sup>	• <sup>a</sup>			• <sup>a</sup>	
AG1U8	Chassis Guides (2)	1											• <sup>a</sup>	

Millimeter dimensions are in ( ).

<sup>a</sup>Requires 2 sets U-style (Type RA) rack mounting angles for installation

<sup>b</sup>Requires center panel support(s) for installation

<sup>c</sup>Requires swing-out rack mounting frame or rack angles

<sup>d</sup>1 unit = 1.75 in. (44 mm)