


# DP2302



## Electronic counter

Monitoring Display-Counter

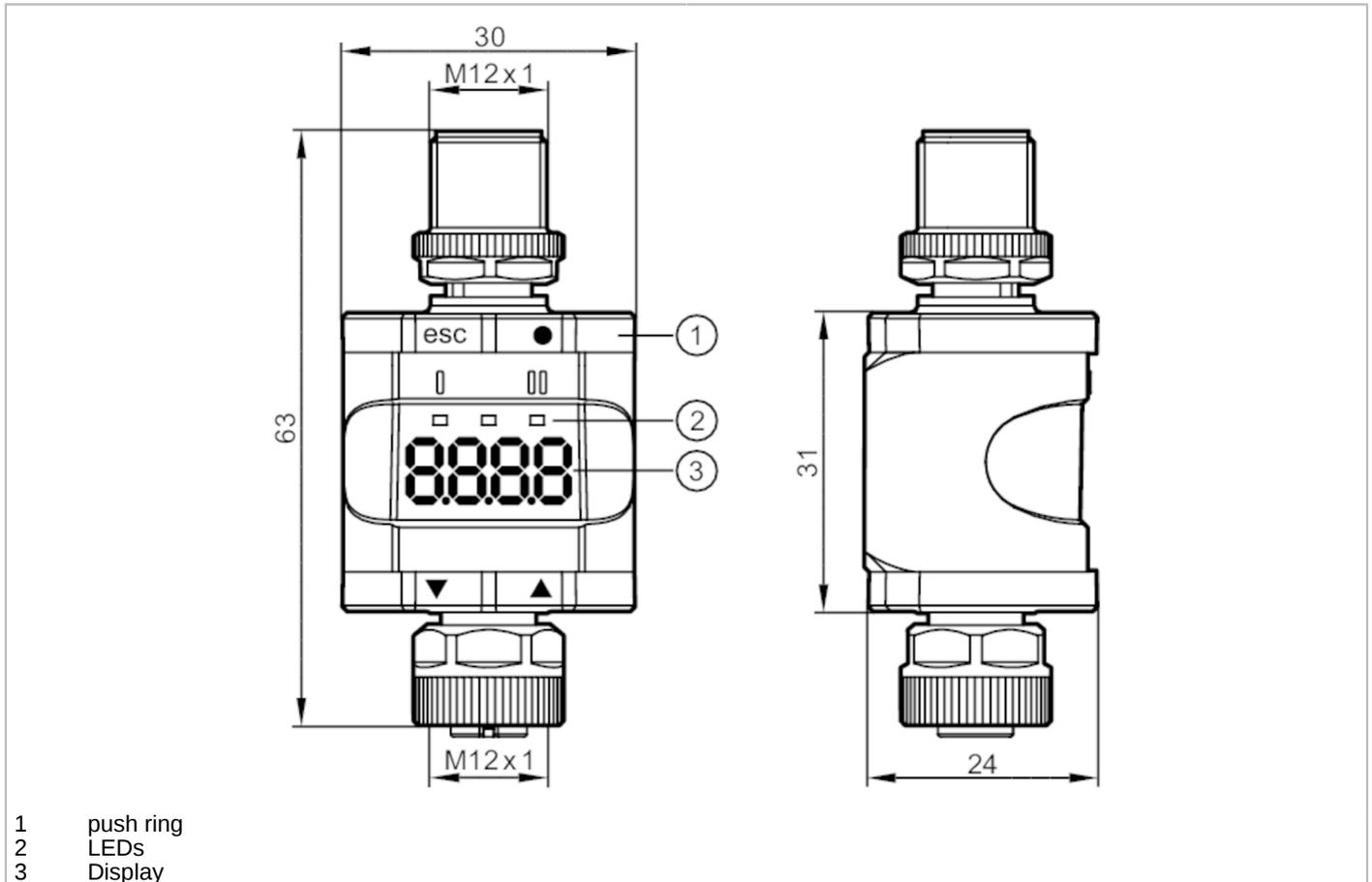

- 1 push ring
- 2 LEDs
- 3 Display



Product characteristics	
Electrical design	PNP/NPN
Output function	normally open / normally closed; (parameterisable)
Communication interface	IO-Link
Housing	rectangular
Dimensions [mm]	63 x 30 x 24
Electrical data	
Operating voltage [V]	18...30 DC; (to SELV/PELV)
Nominal voltage DC [V]	24
Current consumption [mA]	< 380
Max. current load total [A]	0.2
Inputs / outputs	
Number of inputs and outputs	Number of digital inputs: 2; Number of digital outputs: 2
Inputs	
Number of digital inputs	2; (Counting input: 1; Counting direction/Latch: 1; IEC61131-2)
Input current limitation [mA]	200
Outputs	
Electrical design	PNP/NPN
Number of digital outputs	2

# DP2302



## Electronic counter

Monitoring Display-Counter

Output function	normally open / normally closed; (parameterisable)
Short-circuit proof	yes

### Measuring/setting range

Sampling rate [Hz]	< 2000
--------------------	--------

### Interfaces

Communication interface	IO-Link				
Transmission type	COM2 (38,4 kBaud)				
IO-Link revision	1.1				
SDCI standard	IEC 61131-9				
Profiles	Smart Sensor: Measuring Sensor (High resolution, Disable function); Identification and Diagnosis; Switching Signal Channel; Adjustable Switching Signal Channel				
SIO mode	yes				
Required master port type	A				
Process data binary	1				
Min. process cycle time [ms]	6.1				
Supported DeviceIDs	<table><thead><tr><th>Type of operation</th><th>DeviceID</th></tr></thead><tbody><tr><td>default</td><td>1169</td></tr></tbody></table>	Type of operation	DeviceID	default	1169
Type of operation	DeviceID				
default	1169				

### Operating conditions

Ambient temperature [°C]	-25...60
Note on ambient temperature	2000 m: -25...60 °C 3000 m: -25...53 °C 4000 m: -25...51 °C
Storage temperature [°C]	-25...60
Max. relative air humidity [%]	90; (linearly decreasing to 50 % (40 °C) non condensing)
Max. height above sea level [m]	4000
Protection	IP 67
Pollution degree	2

### Tests / approvals

MTTF [years]	317
--------------	-----

### Mechanical data

Weight [g]	84.2
Weight (without accessories and packaging) [g]	35
Housing	rectangular
Dimensions [mm]	63 x 30 x 24
Materials	housing: PA

### Displays / operating elements

Display	operation	1 x LED, green
	switching output	2 x LED, yellow
		7-segment LED display, red/green configurable
Operating elements	2	push ring

### Accessories

Accessories (optional)	mounting clip
------------------------	---------------

# DP2302



## Electronic counter

Monitoring Display-Counter

### Remarks


Remarks	For further information please see the operating instructions.
Pack quantity	1 pcs.

### Electrical connection - plug



- 1: L+            supply voltage
- 2: OUT2        digital output 2
- 3: L-            supply voltage
- 4: OUT1        IO-Link / digital output 1

### Electrical connection - socket

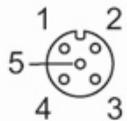

- 1: L+
- 2: IN 2        Counting direction / Latch
- 3: L-
- 4: IN 1        Counting input
- 5:            not used

### Other data

main counter	0...1000000 cnt
batch counter:	0...9999 bcnt