


SWK
SPLICE WASHER KIT

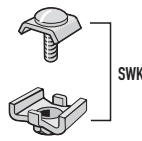

- SWK is designed with a 1/4" x 20* threaded bolt compatible with standard US tools.
- Use SWK to splice any two sections of Cablofil tray.
- Swaged nut allows clamp to be stationary while nut is tightened.
- Consult chart below for correct number of SWK sets needed for each width of tray.
- Also use for fabricating bends, turns and tees.
- UL Classified Splice.

	PKG. QTY.	WEIGHT		EZ	DC	316L	BL
		LBS	KG	UL			UL
SWK	50	3.6	1.6	943 215	943 216	943 218	943 217

* Threads were previously M6

CF30 – CF54 – CF105 – CF150 – TXF35 – CFG	2" (50 MM)	4" → 8" (100 → 200 MM)	12" → 24" (300 → 600 MM)
SWK attachment sets needed for side wires	2x SWK	2x SWK	2x SWK
SWK attachment sets needed for bottom wires	–	1x SWK	2x SWK

APPLICATIONS



CE 40
SQUARE SPLICE WASHER



- Use for splicing Cablofil tray on bends and adjustable turns.
- Two CE 40's and one EZ BN 1/4 are required for each connection.
- EZ BN 1/4 is sold separately.
- UL Classified Splice.

	PKG. QTY.	WEIGHT		EZ	GC	DC	316L	BL	PE
		LBS	KG	UL					
CE 40	25	2.7	1.2	558 051	942 461	558 053	558 054	941 276	934 030