


Fiche technique produit

## LRCB 20

Support d'arbre sans trous de fixation

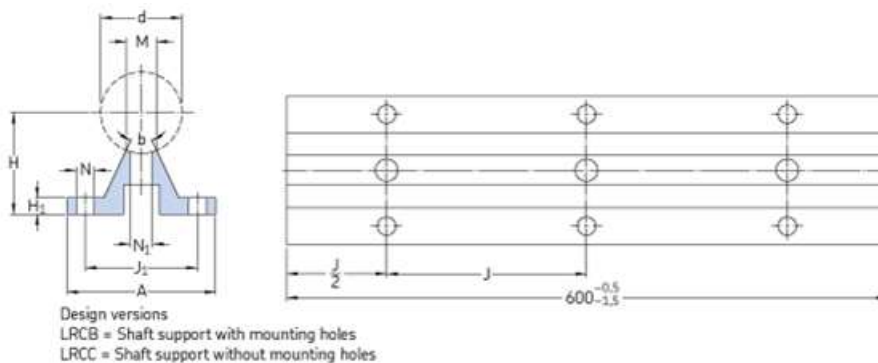

$\beta$ [°]:	50
A [mm]:	52
d [mm]:	20
H [mm]:	32
H1 [mm]:	6
J [mm]:	100
J1 [mm]:	37
L [mm]:	600
M [mm]:	8.3
N [mm]:	6.6
N1 [mm]:	6.6

Date 27/05/2020

The contents of this report are the copyright of the publisher and may not be reproduced (even extracts) unless permission is granted. Every care has been taken to ensure the accuracy of the information contained in this report but no liability can be accepted for any loss or damage whether direct, indirect or consequential arising out of the use of the information contained herein.

Fiche technique produit

## LRCB 20

Support d'arbre sans trous de fixation

Vis:	M6X25
Masse [kg]:	0.92

---

**Date** 27/05/2020

The contents of this report are the copyright of the publisher and may not be reproduced (even extracts) unless permission is granted. Every care has been taken to ensure the accuracy of the information contained in this report but no liability can be accepted for any loss or damage whether direct, indirect or consequential arising out of the use of the information contained herein.