




230V 12W CCT Adjustable LED Panel

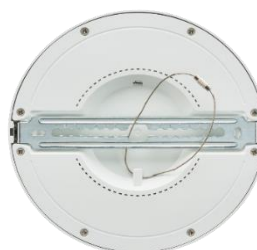

Surface mount

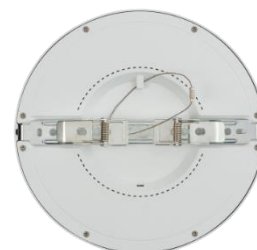

Recess mount

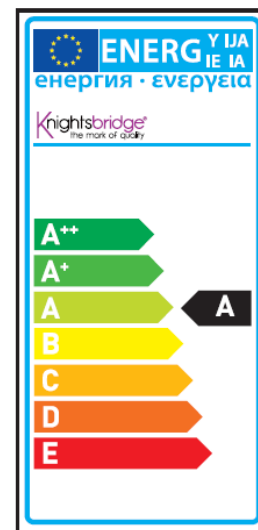

MLA part code	CPL12CT
Description	CCT Adjustable LED Panel
Finish	White / Opal
Nett weight (kg)	0.24
Wattage (W)	12
Lumens (lm)	Warm white - 850 lm ±10% Cool white - 940 lm ±10% Daylight - 920 lm ±10%
Efficacy (lm/W)	Warm white – 71 Cool white - 78 Daylight – 77
Dimensions (mm)	Diameter – 165 Projection – 15
Cut-out (mm)	55 – 125
Fixing centres - surface (mm)	125
CCT	3000K/ 4000K/ 6000K
LED Colour	Warm white/ Cool white/ Daylight
CRI	>80
Operating current (A)	0.1
Power Factor	0.5
Life span (Hrs)	30,000
Input voltage	Mains 230V 50Hz
Construction	Polycarbonate
Insulation class	Class II
IP rating	IP20
Warranty	3 Years
Dimmable	No
Origin of Manufacture	China
Declaration of Conformity (held on file)	Yes
Manufactured in accordance with	BSEN 60598
EAN	5055832984030

