 



Sliding block, sliding block profile, swivel-in, slot 8



- Swivel-in sliding block profile for self-assembly of individual fastening elements
- The swivel-in sliding block for inserting directly at the installation position for really easy assembly
- The swivel-in sliding block with spring can be inserted directly at the assembly point and fixed in position thanks to attached springs
- The swivel-in sliding block with headless setscrews permits shake-proof fixing in all positions

- Profile finishing: not required

Product description

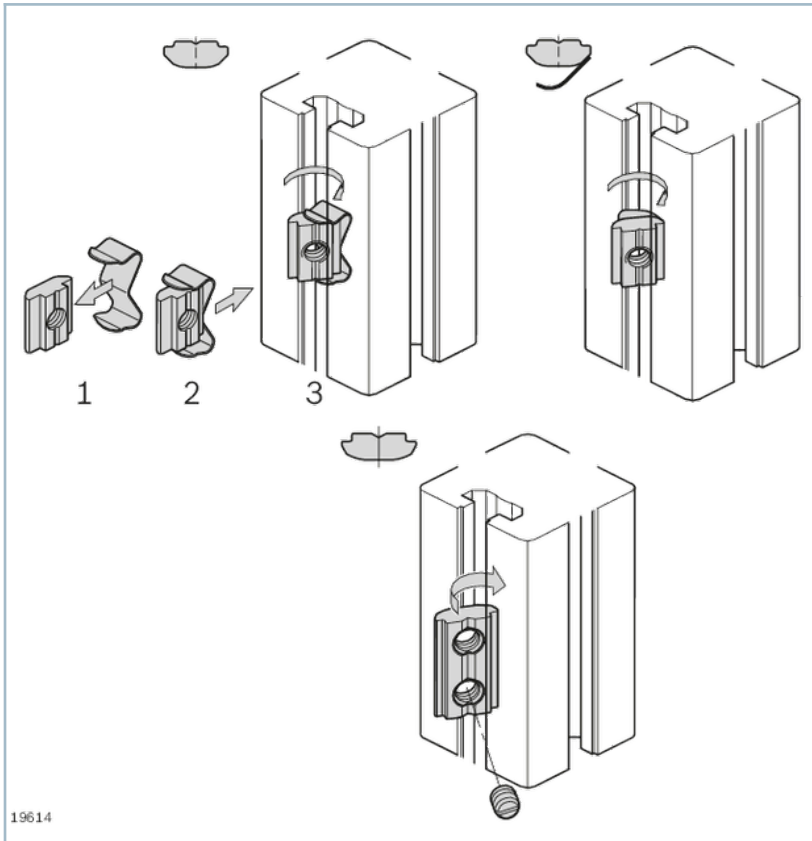


Technical data


Nut	
8 (M8)	2200 N
10 (M8)	8000 ... 18000 N ¹⁾
1) Depending on the profile	

Dimensions


Swivel-in sliding block profile

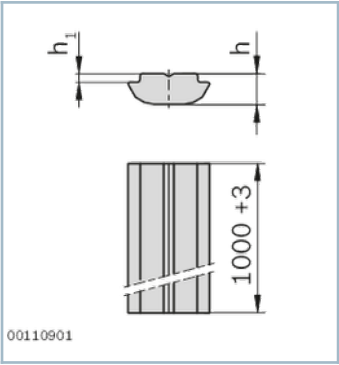


Sliding block, swivel-in

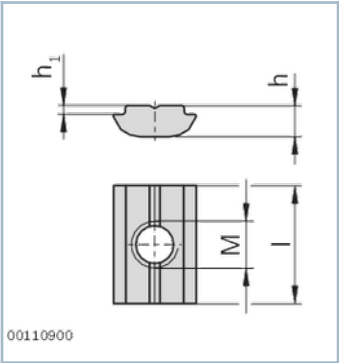

Swivel-in sliding block with spring

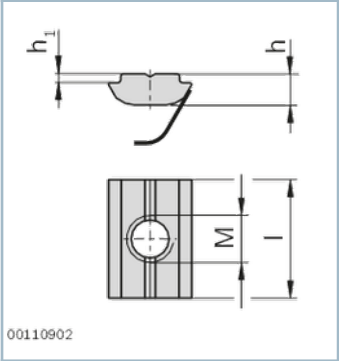

Sliding block, swivel-in, with headless setscrew

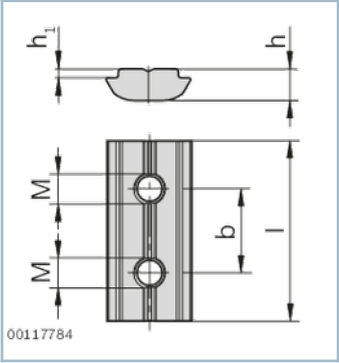









Accessories





Required accessories


Spring

Ordering codes

	Groove	M	b	h	h ₁	l		ESD	No.
			mm	mm	mm	mm			
Sliding block profile swivel-in N8 steel, galvanized	8			4.8	1	1000			3842529327
Sliding block, swivel-in N8 steel, galvanized, M5	8	M5		4.8	1	16	100		3842529319
Sliding block, swivel-in N8 steel, galvanized, M6	8	M6		4.8	1	16	100		3842529320
Sliding block, swivel-in N8 steel, galvanized, M8	8	M8		4.8	1	16	100		3842529321
Sliding block, swivel-in N8 steel, stainless	8	M6		4.8	1	16	100		3842530321

	Groove	M	b	h	h ₁	l		ESD	No.
			mm	mm	mm	mm			
Sliding block, swivel-in, with N8 steel spring, galvanized M4	8	M4		4.8	1	16	100		3842529294
Sliding block, swivel-in, with N8 steel spring, galvanized M5	8	M5		4.8	1	16	100		3842529295
Sliding block, swivel-in, with N8 steel spring, galvanized M6	8	M6		4.8	1	16	100		3842529296
Sliding block, swivel-in, with N8 steel spring, galvanized M8	8	M8		4.8	1	16	100		3842529297
Sliding block, swivel-in, with N8 steel spring, stainless M4	8	M4		4.8	1	16	100		3842547824

	Groove	M	b	h	h ₁	I		ESD	No.
			mm	mm	mm	mm			
Sliding block, swivel-in, with N8 steel spring, stainless M5	8	M5		4.8	1	16	100		3842547823
Sliding block, swivel-in, with N8 steel spring, stainless M6	8	M6		4.8	1	16	100		3842547822
Sliding block, swivel-in, with N8 steel spring, stainless M8	8	M8		4.8	1	16	100		3842547821
Swivel-in sliding block, with N8 steel headless setscrew; galvanized, M5, M4	8	M5; M4	12	4.8	1	24	100		3842557259

	Groove	M	b	h	h ₁	l		ESD	No.
			mm	mm	mm	mm			
Swivel-in sliding block, with N8 steel headless setscrew; galvanized, M5, M5	8	M5; M5	12	4.8	1	24	100		3842536675
Swivel-in sliding block, with N8 steel headless setscrew; galvanized, M5, M6	8	M5; M6	12	4.8	1	24	100		3842557260