

26 12 200




Snipe Nose Side Cutting Pliers (Stork Beak Pliers)



- Elastic tips: dimensionally stable even when twisted
- Distortion-tolerant, elastic precision tips
- Half-round, long, tapered jaws
- With cutting edges (hardness approx. 61 HRC) for soft, medium-hard and hard wire
- Vanadium electric steel, forged, multi stage oil-hardened



Article No.	26 12 200
EAN	4003773010883
Head	polished
Handles	with multi-component grips
Pliers	black atramentized
Style	1
Cutting capacities medium hard wire (diameter) Ø mm	3,2
Cutting capacities hard wire (diameter) Ø mm	2,2
T1 mm	9,5
W3 mm	18,0
W4 mm	3,0
T2 mm	2,5
L3 mm	73,0
Nominal size	200 mm
Length mm	200
Net weight g	201

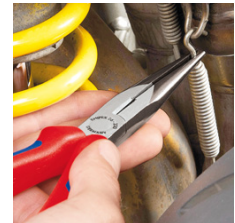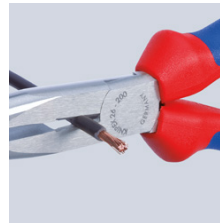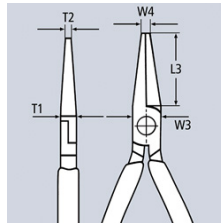

technical change and errors excepted

