


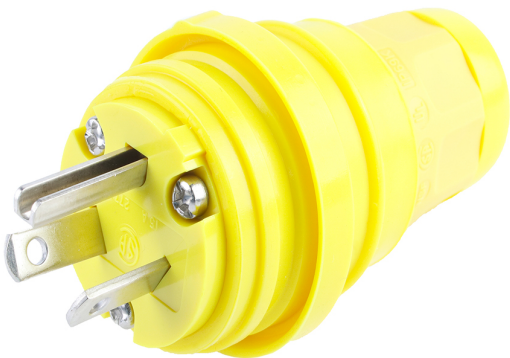

Part Number : [1301460028](#)
Product Description : Watertite Extreme Plug,
2 Pole/3 Wire, NEMA 7-15, 277V, Cord Grip
Body Size F2, Silicone Husk
Series Number : 130146
Status : Active
Product Category : Wiring Devices
Engineering Number : 14W34



Documents & Resources

Drawings
[1301460028_sd.pdf](#)

3D Models and Design Files
[1301460028_stp.zip](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	Not Reviewed per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Not Reviewed per D(2024)6225-DC (07 Nov 2024)
EU RoHS	Not Reviewed per EU 2015/863

- Multiple Part Product Compliance Statements
- Eu RoHS
 - REACH SVHC
 - Low-Halogen
- Multiple Part Industry Compliance Documents
- IPC 1752A Class C
 - IPC 1752A Class D

- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Wiring Devices
Series	130146
Description	Watertite Extreme Plug, 2 Pole/3 Wire, NEMA 7-15, 277V, Cord Grip Body Size F2, Silicone Husk
IP Rating	IP69K
NEMA Configuration	NEMA 7-15
Product Name	Watertite Extreme
Specialty	N/A
Type	Plug
UPC	78678871004

Agency

CSA	LR6837
UL	E10176

Electrical

Current - Maximum per Contact	15.0A
GFCI	No
Voltage - Maximum	277V

Physical

Cord Grip Body Size	F2 1/2"
Cord Type	N/A
Flange	No
Flip Lid	No
Gender	Male
Length	N/A

Lighted Connector	No
Locking Blade	No
Net Weight	124.110/g
Poles	2-pole/3-wire
Receptacle Type	N/A

This document was generated on Mar 27, 2025