


SIVACON, Roof, EMC, EMC, IP40, W: 800 mm, T: 500 mm, zinc-plated

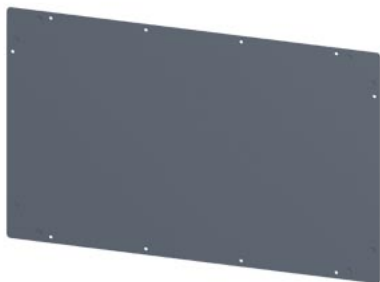

Model			
product brand name	SIVACON		
product designation	top plate		
design of the product	EMC		
design of the surface	zinc plated		
design of the product EMC version	Yes		
Protection class			
protection class IP	IP40		
Suitability			
suitability for use for outside use	No		
Product details			
product component			
● cable entry			No
● ventilation			No
Mechanical Design			
width	800 mm		
depth	500 mm		
material	steel		
Approvals Certificates			
General Product Approval		Test Certificates	
		other	



[Special Test Certificate](#)

[Confirmation](#)

[Miscellaneous](#)

other	Environment
Miscellaneous	 Environmental Confirmations

Further information
Information on the packaging https://support.industry.siemens.com/cs/ww/en/view/109813875
Information- and Downloadcenter (Catalogs, Brochures,...) http://www.siemens.com/lowvoltage/catalogs
Industry Mall (Online ordering system) https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1085-2UD12-0A
Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8MF1085-2UD12-0A>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1085-2UD12-0A

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

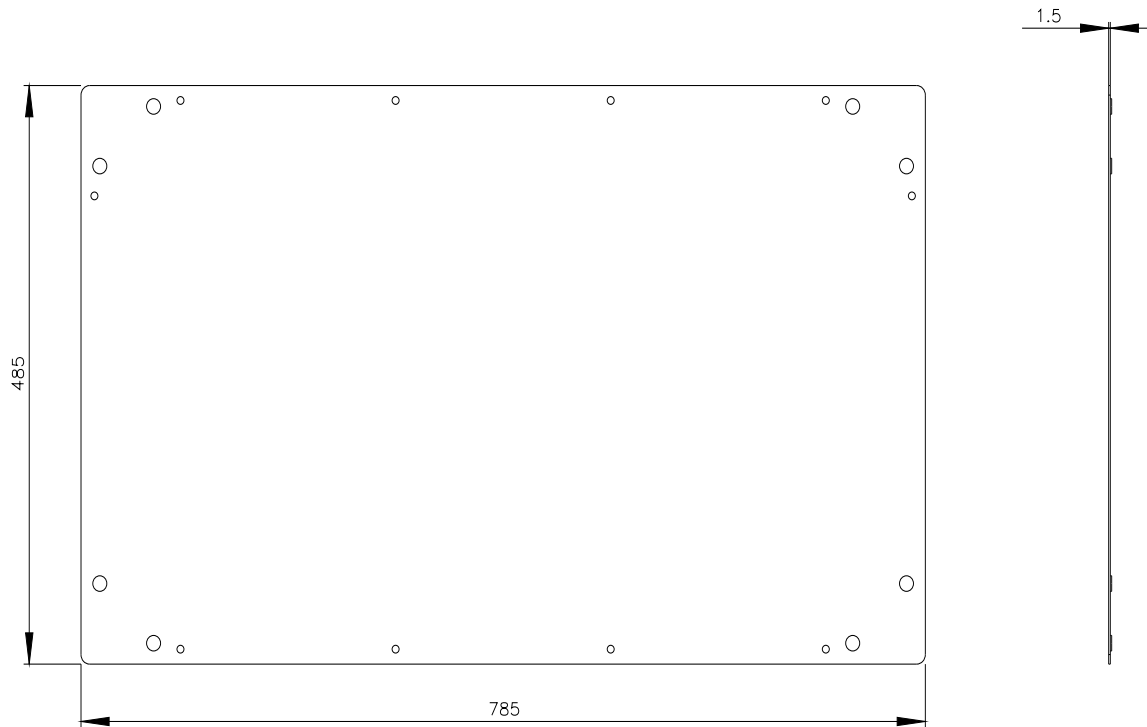

last modified:

7/24/2023 

