




Alcoswitch | Alcoswitch AV19

TE Internal #: 2-2213765-3

Anti-Vandal Switch, Single Pole - Double Throw Configuration (Pole-Throw), Single Actuator, Flush Actuator, Illuminated, Alcoswitch AV19

[View on TE.com >](#)

Switches > Push Button Switches

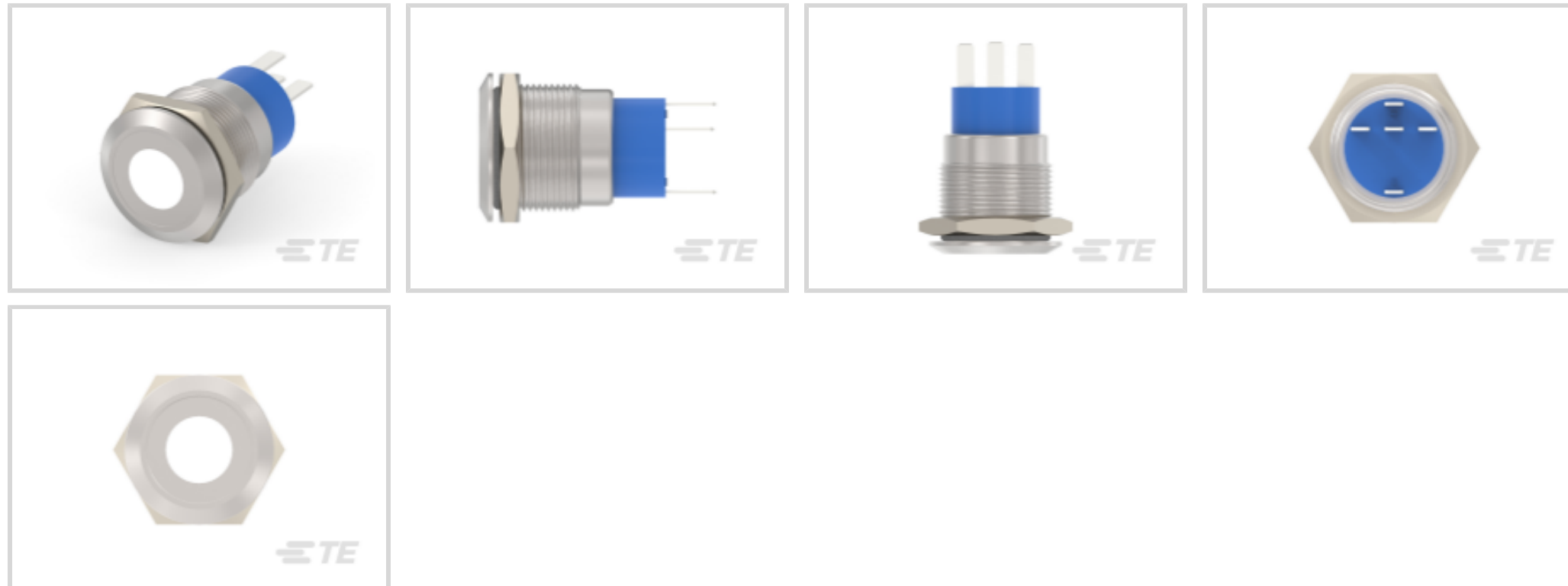

Push Button Switch Product Type: **Anti-Vandal Switch**
 Configuration (Pole-Throw): **Single Pole - Double Throw**
 Number of Actuators: **Single**
 Actuator Profile: **Flush**
 Bushing Style: **Threaded**

Features

Product Type Features

| | |
|---------------------------------|--------------------|
| Switch Connection Type | Wire Lugs |
| Push Button Switch Product Type | Anti-Vandal Switch |
| Illuminated | With |
| Actuator Style | Round Actuator |

Configuration Features

| | |
|----------------------------|----------------------------|
| Configuration (Pole-Throw) | Single Pole - Double Throw |
| Number of Actuators | Single |
| Snap Action | Without |
| Support Bracket | Without |
| Switch Feedback Type | Auditory |
| Operating Function | Push-On/Push-Off |

Electrical Characteristics

| | |
|-------------------------|---------|
| Contact Current Rating | 3 A |
| Operating Voltage Range | 250 VAC |



Body Features

| | |
|---------------------|-------------|
| Case Material | PBT |
| Product Orientation | Vertical |
| Actuator Force | 255 g[9 oz] |
| Actuator Profile | Flush |
| Bushing Style | Threaded |

Contact Features

| | |
|---------------------------------|--------|
| Switch Contact Plating Material | Silver |
|---------------------------------|--------|

Housing Features

| | |
|----------------|-----|
| Process Sealed | Yes |
|----------------|-----|

Dimensions

| | |
|--|-------|
| | 19 in |
|--|-------|

Industry Standards

| | |
|-----------|------|
| IP Rating | IP67 |
|-----------|------|

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

| | |
|---|--|
| EU RoHS Directive 2011/65/EU | Compliant with Exemptions |
| EU ELV Directive 2000/53/EC | Compliant |
| China RoHS 2 Directive MIIT Order No 32, 2016 | Restricted Materials Above Threshold |
| EU REACH Regulation (EC) No. 1907/2006 | Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) SVHC > Threshold: Pb (4% in Component Part) Article Safe Usage Statements: Do not eat, drink or smoke when using this product. Wash thoroughly after handling. Recycle if possible and dispose of the article by following all applicable governmental regulations relevant to your geographic location. |
| Halogen Content | Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free |
| Solder Process Capability | Not applicable for solder process capability |

Product Compliance Disclaimer


This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent

chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>


Compatible Parts



Also in the Series | Alcoswitch AV19

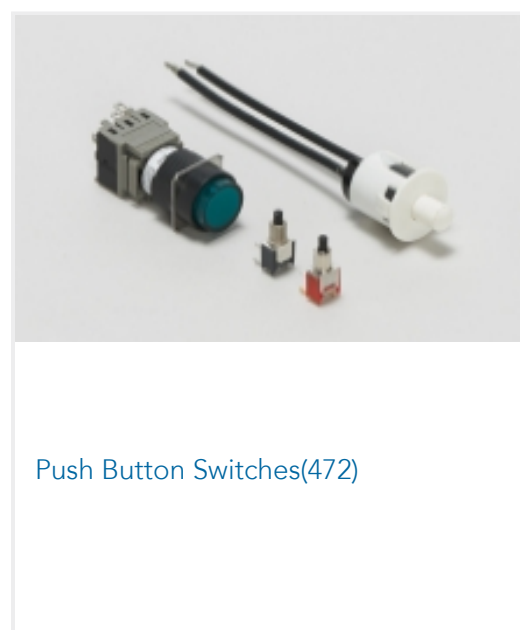

Customers Also Bought

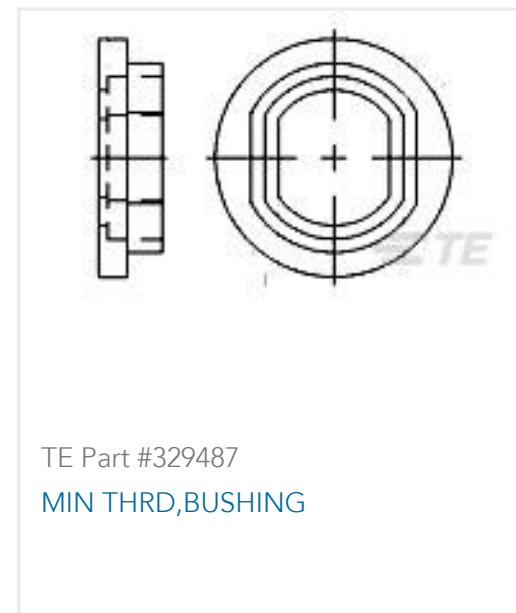

Documents

Product Drawings

[AV19 SPL 3A SPOT LED WHITE 24V](#)

English

CAD Files

[3D PDF](#)

3D

[Customer View Model](#)

[ENG_CVM_CVM_2-2213765-3_A.2d_dxf.zip](#)

English

[Customer View Model](#)

[ENG_CVM_CVM_2-2213765-3_A.3d_igs.zip](#)

English

[Customer View Model](#)

[ENG_CVM_CVM_2-2213765-3_A.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages



ALCOSWITCH Anti-Vandal Switch

English

Agency Approvals

[UL Report](#)

English