 


p r o d u c t d a t a



Cable Tie Base

- *Quick and easy to use*
- *Strong self adhesive fixing*
- *Screw fixing facility*
- *Suitable for either cable ties or Beta strip*

Cable Tray Cleat

- *Cable tie anchoring device for use with slotted cable tray*
- *Suitable for use with cable ties or 4.0mm, 8.0mm and 12.0mm Beta strip*

Cradle


- *Suitable for fixing cable ties to panels and walls*

Cable Strapping

- *Suitable for binding cable bundles*
- *Available in nylon or PVC*

Beta strip Buckle

- *Available in nylon or zinc plated steel*

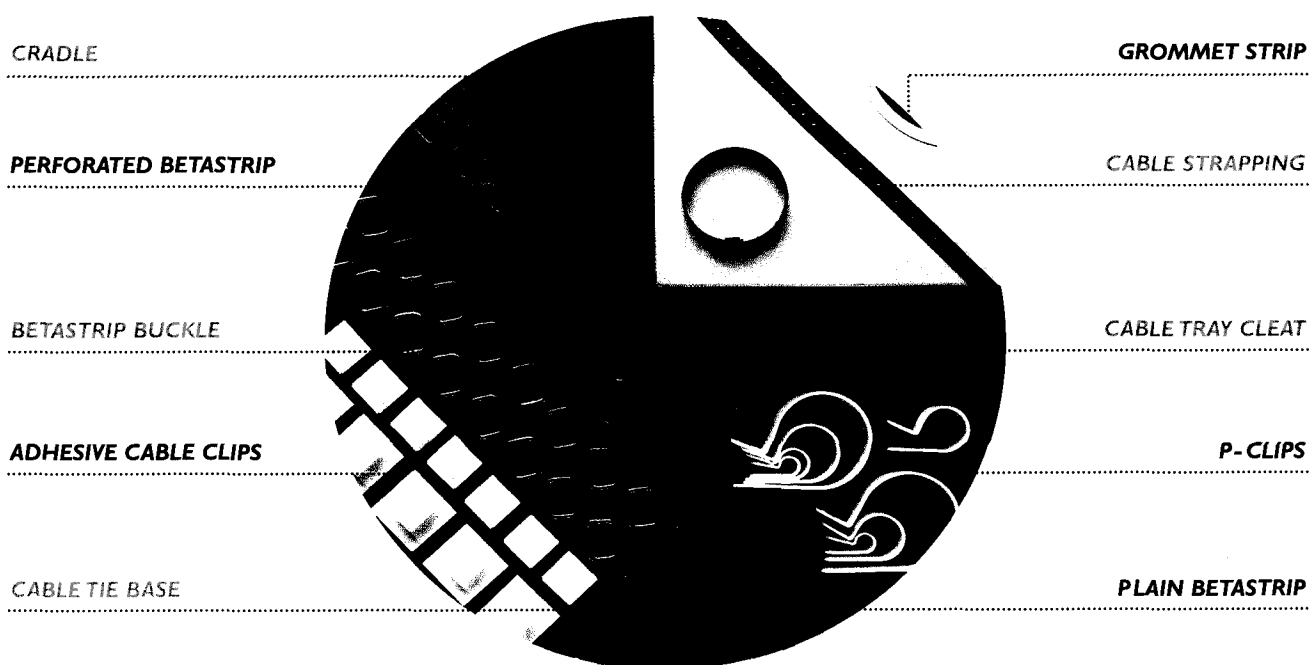

Adhesive Cable Clips

- Strong self adhesive fixing

P-Clips

- Secure fixing device for looms and conduits
- Screw Fixing
- 10 Sizes from 3.0mm to 34.0mm diameter

Perforated Beta strip

- Suitable for fixing cables and pipes to cable tray or other surfaces
- Pre-punched - no drilling required
- Polyester coated aluminium
- 125 kg breaking load

Plain Beta strip

- Heavy duty, insulated strapping
- Corrosion resistant aluminium

Grommet Strip

- Stops chafing on panel openings
- Suitable for plate thicknesses from 1.0mm to 6.5mm

Adhesive Cable Clips

CABLE DIAMETER mm	BASE DIMENSIONS (WxH) mm	PACKED	ORDER CODE
4	15.9 x 15.9	100	1426
8	25.4 x 25.4	100	1427
14	31.8 x 31.8	50	1850
MATERIAL Nylon 6.6. with adhesive tape		SERVICE TEMPERATURE -20°C to +80°C	

P-Clips

SIZE	DIAMETER mm	WIDTH mm	SCREW HOLE DIAMETER mm	PACKED	ORDER CODE
1	3.0	9.5	5.2	100	1860
2	6.0	9.5	5.2	100	1861
3	7.5	9.5	5.2	100	1862
4	9.0	9.5	5.2	100	1863
5	11.0	9.5	5.2	100	1864
6	12.5	9.5	5.2	100	1865
7	16.0	12.7	5.2	50	1866
8	20.0	12.7	5.2	50	1867
9	25.0	12.7	5.2	50	1868
10	34.0	12.7	5.2	50	1869
MATERIAL Nylon 6.6		STANDARD COLOURS Black	SERVICE TEMPERATURE -20°C to +85°C	APPROVALS UL file no. E39806A, B+C	

Perforated Betastrip

SIZE WIDTH mm	PACKED m	ORDER CODE GREY	ORDER CODE ORANGE
19	5 x 10	0413	0416
MATERIAL 99% Aluminium strip with stoved polyester resin			

Plain Betastrip

SIZE WIDTH mm	PACKED m	ORDER CODE BLACK	PACKED m	ORDER CODE ORANGE
4	2 x 50	0404	-	-
8	2 x 25	0411	-	-
12	2 x 25	0412	25 x 2	0414
19	50 x 2	0408	1 x 2	0415
MATERIAL 99% Aluminium strip with stoved polyester resin		SERVICE TEMPERATURE -15°C to +50°C		

Grommet Strip

SIZE OD mm	PLATE THICKNESS mm	swg	MINIMUM CORNER RADIUS mm	MINIMUM APERTURE DIAMETER mm	PACKED m	ORDER CODE
2	1.0 - 1.1	up to 18	4	22	25	0494
3	1.5 - 2.0	17 - 14	5	25	25	0495
4	2.5 - 3.3	13 - 10	6	30	25	0496
5	4.0 - 4.9	-	8	36	25	0497
6	4.5 - 6.5	-	8.5	45	25	0498
MATERIAL LDPE natural		SERVICE TEMPERATURE -50°C to +50°C				

Cable Tie Base

BASE DIMENSIONS mm	SLOT WIDTH mm	PACKED	ORDER CODE BLACK	ORDER CODE NATURAL
25 x 25	8.5	100	1849	1848
18 x 18	4.5	100	1877	1876
MATERIAL Nylon 6.6 with adhesive tape	STANDARD COLOURS Black and natural	SERVICE TEMPERATURE Max. +50°C (+75°C short term)		

Cable Tray Cleat

SIZE WIDTH mm	PACKED	ORDER CODE
12	100	0401
MATERIAL Nylon 6.6, black	STANDARD COLOURS Black	SERVICE TEMPERATURE -20°C to +80°C

Cradle

FIXING HOLE DIAMETER mm	SLOT WIDTH mm	PACKED	ORDER CODE
4.3	9.0	100	1101
MATERIAL Nylon 6.6	STANDARD COLOURS Black	SERVICE TEMPERATURE -25°C to +80°C	

Cable Strapping

MATERIAL	WIDTH mm	PACKED	ORDER CODE
PVC	8	25m	0390
PVC	12	25m	0392
Nylon	8	30m	0394
Nylon	12	30m	0395
Studs	-	1000	0393
MATERIAL PVC Nylon 6.6	SERVICE TEMPERATURE -15°C to +50°C - PVC -50°C to +80°C - Nylon		

Betastrip Buckle

MATERIAL	WIDTH mm	PACKED	ORDER CODE
Nylon	4	100	0473
Steel	8	100	0425
Steel	12	100	0426
MATERIAL Nylon 6.6	STANDARD COLOURS Black	SERVICE TEMPERATURE -25°C to +80°C	