

# HM2001WSI LP


Welders boot



## Technology



Dual Density Rubber sole

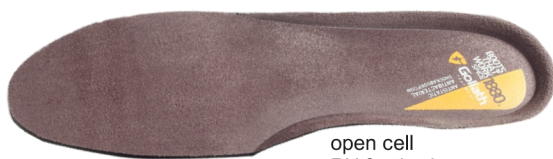

open cell  
PU footbed



## Features

<b>Standard</b>	EN ISO 20349:2010
<b>Category</b>	S3 HI CI HRO SRC Wg
<b>Code</b>	HM2001WSI LP
<b>Product type</b>	Welders boot
<b>Colour</b>	Black
<b>Size range</b>	UK sizes 5 - 13 Continental 39 - 48
<b>Weight</b>	900gr
<b>Upper</b>	Full Grain Barton Print Buffalo Leather with higher Chrome Content (1.8 – 2.0mm)
<b>Inner lining</b>	Moisture wicking textile to vamp only
<b>Safety features</b>	Stainless Steel Toe Cap, resistant to 200J Steel midsole

### Additional features

Quick release velcro fastener

Flame resistant stitching.

### Soling technology

Lightweight Injected Flame Retardant Dual Density Rubber/Rubber, Flexible soling system with antistatic properties, shock absorption, heat resistance to 300°C and SRC rated slip resistance.

### Insole technology

Moisture wicking, breathable and washable  
Open Cell PU Footbed

