
Vintage 1906 LED

LED lamps, vintage edition



Areas of application

- Domestic applications
- General illumination
- Outdoor applications only in suitable luminaires
- Perfect for decorative installations

Product benefits

- Very low energy consumption
- Instant 100 % light, no warm-up time
- Can be easily fitted instead of ordinary light bulbs
- Clear lamps with innovative LED "filament" technology

Product features

- LED lamps for line voltage
- Not dimmable
- Mercury-free lamps
- Lifetime: up to 15,000 h
- Beam angle: up to 360°
- Energy efficiency class: A++






Product family datasheet

Technical data

Product description	Electrical data		Photometrical data			Light technical data		Dimensions & weight	Lifespan	
	Nominal wattage	Nominal voltage	Color temperature	Color rendering index Ra	Light color (designation)	Warm-up time (60 %)	Starting time	Overall length	Nominal lamp life time	Number of switching cycles
RF CLAS GL 35 4 W/824 E27	4.00 W	220...240 V	2400 K	≥80	Warm White	< 0.50 s	< 0.5 s	168.0 mm	15000 h	100000
RF CLAS ST 35 4 W/824 E27	4.00 W	220...240 V	2400 K	≥80	Warm White	< 0.50 s	< 0.5 s	143.0 mm	15000 h	100000
RF CLAS GL 54 7 W/824 E27	7.00 W	220...240 V	2400 K	≥80	Warm White	< 0.50 s	< 0.5 s	168.0 mm	15000 h	100000
RF CLAS ST 54 7 W/824 E27	7.00 W	220...240 V	2400 K	≥80	Warm White	< 0.50 s	< 0.5 s	143.0 mm	15000 h	100000

Product description	Lumen main. fact. at end of nom. life time	Additional product data		Capabilities	Certificates & standards		Country specific categorizations
		Base (standard designation)	Mercury-free	Dimmable	Energy efficiency class	Energy consumption	ILCOS
RF CLAS GL 35 4 W/824 E27	0.70	E27	Yes	No	A++	4 kWh/1000h	DRAG/C-4/824-220/240-E27-124
RF CLAS ST 35 4 W/824 E27	0.70	E27	Yes	No	A++	4 kWh/1000h	DRAS/C-4/824-220/240-E27-64
RF CLAS GL 54 7 W/824 E27	0.70	E27	Yes	Yes	A+	7 kWh/1000h	DRAG/C-7/827-220-240-E27-124
RF CLAS ST 54 7 W/824 E27	0.70	E27	Yes	Yes	A+	7 kWh/1000h	DRAS/C-7/824-220-240-E27-64

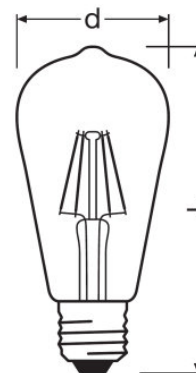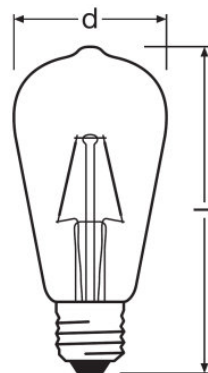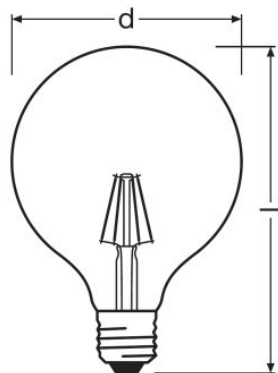

Product family datasheet

RF CLAS GL 35 4 W/824 E27, RF CLAS
GL 54 7 W/824 E27

RF CLAS ST 35 4 W/824 E27

RF CLAS ST 54 7 W/824 E27

Application advice

For more detailed application information and graphics please see product datasheet.

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Volume	Gross weight
4052899962071	RF CLAS GL 35 4 W/824 E27	Shipping carton box 4	291 mm x 291 mm x 228 mm	19.31 dm ³	958.00 g
4052899962095	RF CLAS ST 35 4 W/824 E27	Shipping carton box 4	233 mm x 233 mm x 206 mm	11.18 dm ³	573.00 g

Product family datasheet

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Volume	Gross weight
4052899972698	RF CLAS GL 54 7 W/824 E27	Shipping carton box 4	291 mm x 291 mm x 228 mm	19.31 dm ³	1082.00 g
4052899972360	RF CLAS ST 54 7 W/824 E27	Shipping carton box 4	233 mm x 233 mm x 206 mm	11.18 dm ³	683.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.