


Axial kit
EAMM-A-L48-70GA-G2
Part number: 8188640

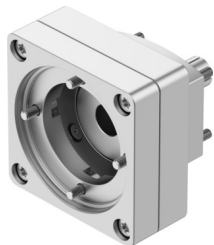

 [General operating condition](#)

Data sheet

Feature	Value
Nominal length	53.5 mm
Mounting position	optional
Max. rotational speed	6000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	39 kgmm ²
Transmittable torque	21 Nm
Product weight	725 g
Interface code, actuator	L48
Interface code, motor in	70GA
Note on materials	RoHS-compliant