




Switches > Switch Knobs

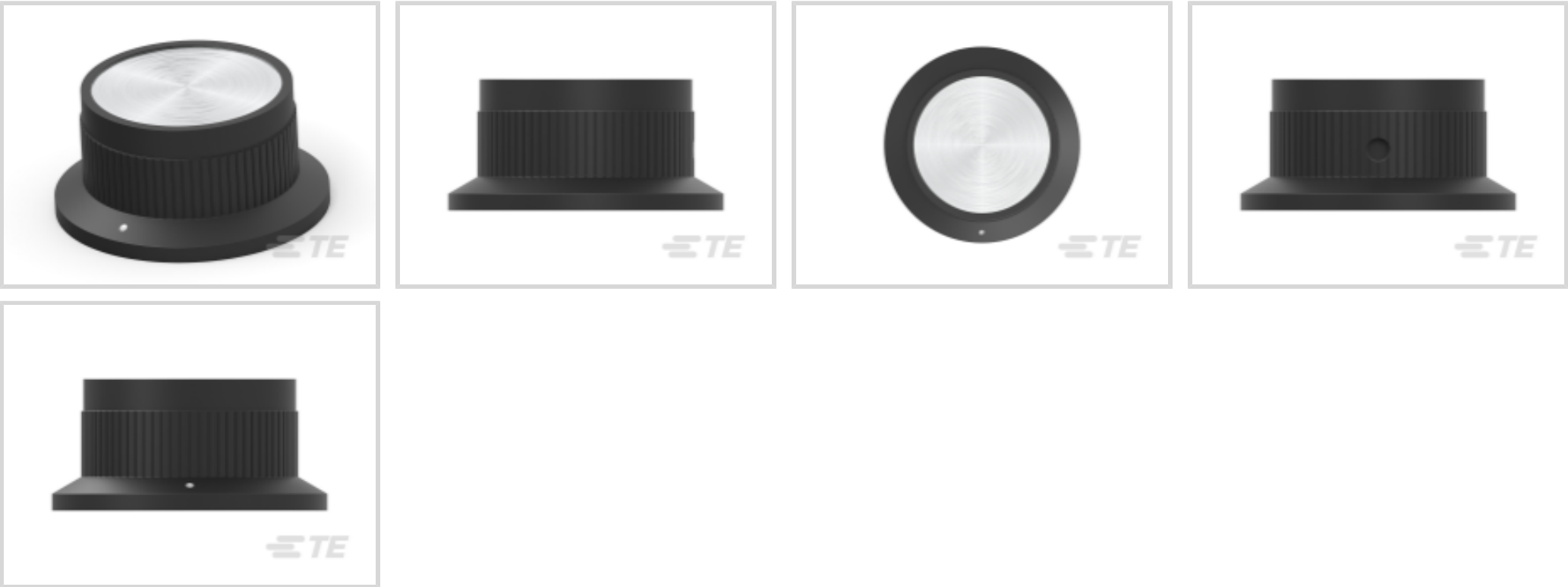

Primary Product Material: **Molded Phenolic Resin**

Knob Design: **Straight Knurl**

Shaft Size: **6.35 mm [.25 in]**

Product Diameter: **31.75 mm [1.25 in]**

Primary Product Color: **Black**

Features

Configuration Features

|             |                |
|-------------|----------------|
| Spinner     | Without        |
| Skirt       | With           |
| Spin Plate  | Without        |
| Knob Design | Straight Knurl |

Body Features

|                          |                       |
|--------------------------|-----------------------|
| Primary Product Material | Molded Phenolic Resin |
| Primary Product Color    | Black                 |

Dimensions

|                  |                   |
|------------------|-------------------|
| Shaft Size       | 6.35 mm[.25 in]   |
| Product Diameter | 31.75 mm[1.25 in] |

Identification Marking

|                    |          |
|--------------------|----------|
| Indicator Style    | Dot      |
| Indicator Location | On Skirt |



Product Compliance

For compliance documentation, visit the product page on TE.com>

|                                               |                                                                                                                               |
|-----------------------------------------------|-------------------------------------------------------------------------------------------------------------------------------|
| EU RoHS Directive 2011/65/EU                  | Compliant                                                                                                                     |
| EU ELV Directive 2000/53/EC                   | Out of Scope                                                                                                                  |
| China RoHS 2 Directive MIIT Order No 32, 2016 | No Restricted Materials Above Threshold                                                                                       |
| EU REACH Regulation (EC) No. 1907/2006        | Current ECHA Candidate List: JAN 2025 (247)<br>Candidate List Declared Against: JAN 2022 (223)<br>Does not contain REACH SVHC |
| Halogen Content                               | Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free                                           |
| Solder Process Capability                     | Not applicable for solder process capability                                                                                  |

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 1437624-8  
PK70B1/4=KNOB PLASTIC BLK 1/4



TE Part # 1437624-3  
PK1100B1/4=KNOB PLASTIC BLK CO



TE Part # 1437624-6  
PK50B1/4=KNOB PLASTIC BLK 1/4



TE Part # 1437624-7  
PK50B1/8=KNOB PLASTIC BLK 1/8



TE Part # 1437624-2  
PH15181/4=KNOB PLASTIC CONTROL

Customers Also Bought



TE Part #1-6609107-8  
PS0S0DS60=C1045



TE Part #179228-3  
CT CRIMP TYPE REC HSG



TE Part #206043-4  
CPC RECPT ASSEMBLY SIZE 17-14



TE Part #179227-1  
CRIMP TYPE II REC CONTACT



TE Part #2-1393250-3  
W28-XQ1A-1=W28-



TE Part #3-1393117-0  
KUP-11A55-24=KU



TE Part #6609032-3  
2VR1=F7196 S0



TE Part #2213775-9  
AV16 SPM 0.4VA POWER LED BLUE 12V



TE Part #3-66104-0  
III+ SKT,24-20,TIN ,STRIP



TE Part #080-0001  
CABLE,U.FL to SMA Bulkhd 1.13mm Dia,105m

Documents

CAD Files

3D PDF

3D

Customer View Model

ENG\_CVM\_CVM\_1437624-9\_99\_c-1437624-9-99.2d\_dxf.zip

English

Customer View Model

ENG\_CVM\_CVM\_1437624-9\_99\_c-1437624-9-99.3d\_igs.zip

English

PK90B1/4

Molded Phenolic Resin, Straight Knurl Knob Design, 6.35 mm [.25 in] Shaft, 31.75 mm [1.25 in] Diameter, Black, Dot Indicator, Switch Knobs



Customer View Model

[ENG\\_CVM\\_CVM\\_1437624-9\\_99\\_c-1437624-9-99.3d\\_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[SWITCHES\\_CORE\\_PROGRAM\\_CATALOG](#)

English