

Part Number: ASLS-5
Shock / Acceleration Switch
Product Data Sheet


 
PICTURE



✓ RoHS Compliant

OPERATION

ACCELERATE THIS
 DIRECTION TO
 CLOSE CONTACTS

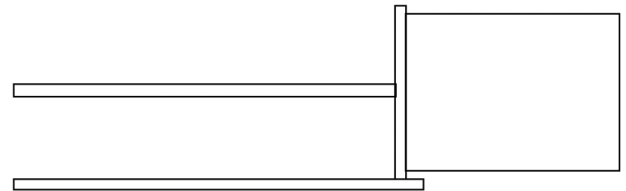


WORKING POSITION

FEATURES

- Resistant to Severe Environmental Conditions
- Case Material Steel-Gold Plated
- Mechanical Stress Resistant
- Anti-Vibration
- Hermetically Sealed & Inert Gas Filled

DIMENSIONS

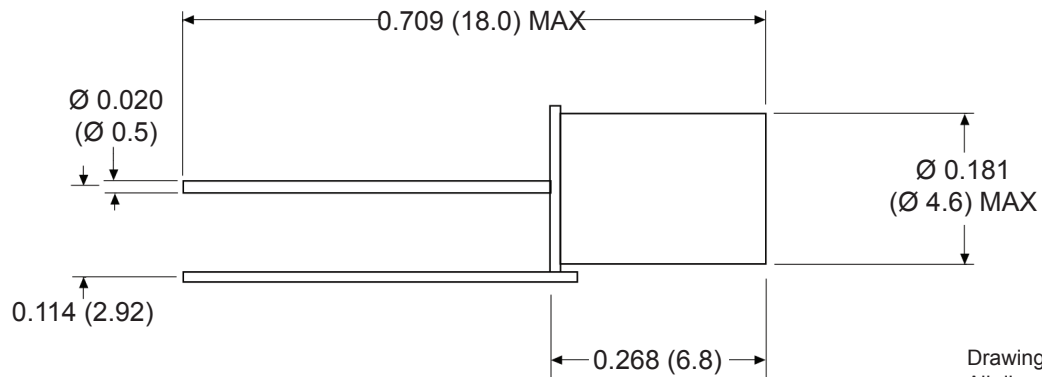

Drawings not to scale.
 All dimensions in inches (mm) nominal.

SPECIFICATION

Contact Form / Style		Normally Open
Switching Voltage	MAX. VAC	24
Switching Current	MAX. A	0.25
Switching Capacity (Resistive)	MAX. VA	5
Contact Resistance	MAX. Ω	10
Operating Temperature		-20° +85°C
Storage Temperature		-25° +90°C
Activation Level	G	5.0 - 9.9

As part of the company policy of continued product improvement, specifications may change without notice. Our sales office will be pleased to help you with the latest information on this product range and the details of our full design and manufacturing service. All products are supplied to our standard conditions of sale unless otherwise agreed in writing.

Phone: (1) 973 777 6900

www.comus-intl.com

Fax: (1) 973 777 8405