

Datasheet

RS 2 Core Multicore Speaker Cable, PVC Insulation 60 V

Stock number: 714-0316



Product Description

Reference Standard

Customer's sample spec.and the general standard

Multi-construction

Cable Construction


Conductor	Tinned Copper
Construction	T0.2±0.008×13
Standard Dia.(mm)	0.83
Insulation	PVC
Thickness	0.57
Insulation Dia.(±0.1mm)	2.0×2
Insulation Color	Grey
Marking	One Black Stripe on one leg of Twin

Print Marking

2 core 13/0.2mm 60 V PVC [MM][WkYr]

PACKAGING

100M/Cardboard Reel.

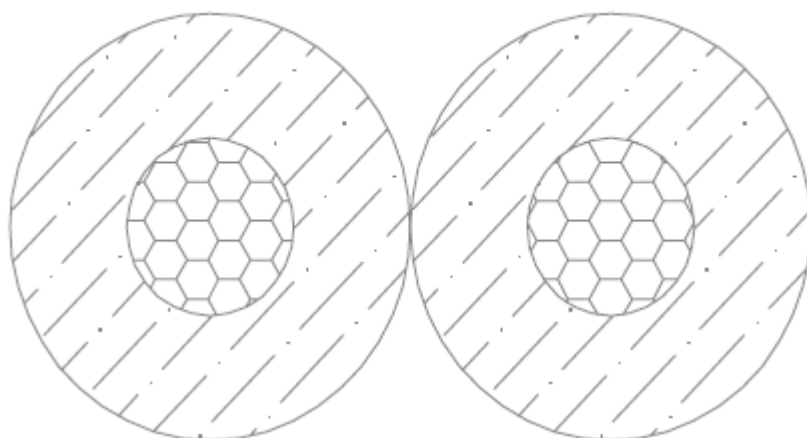

Electrical Characteristics

Max.Conductor DC Resistance at 20 °C (Ω /Km)	<46.4
Min.Insulation DC Resistance at 20 °C (M Ω *Km)	200
Rated Temperature(°C)	80
Rated Voltage (V)	60