


MPN: 050-NF19D


Image

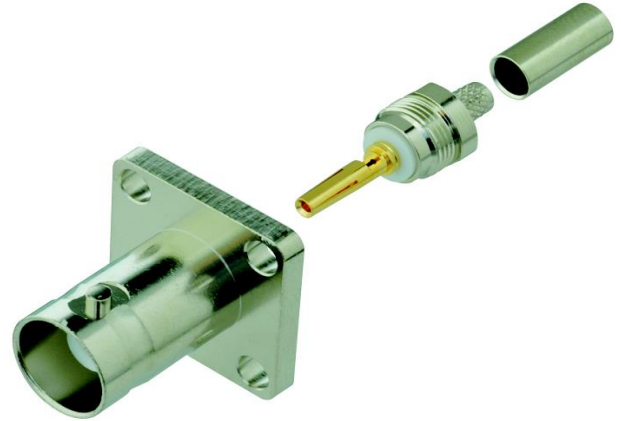

Product: BNC Connectors

Description: BNC Connector Flange Type Jack

Line Draw

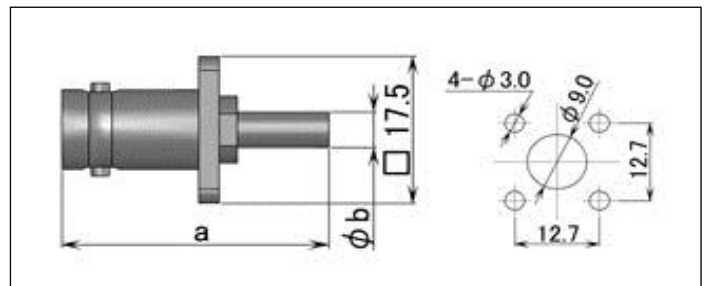

Specification

Body Orientation	Straight
Body Plating	Nickel
Cable Type	1.5D-2V
CAD Drawing	
Contact Material	Phosphor bronze
Contact Plating	Gold
Gender	Female
Impedance	50Ω
Mounting Type	
Operating Frequency	0 → 4GHz
Termination Method	Solder