


COLOR MINIATURE CAMERA

7769387

► CAUTION

- Do not open or strike this equipment. Sensitive electronics inside are vulnerable to excessive shock.
- Do not install the equipment near any naked flames or heat sources. Excessive heat could damage this unit.
- Do not cover cloth or to install this unit in poorly ventilated places. This may lead to overheating.
- Do not continue to operate if there appears to be fault.
- If the unit ceases to function, contact qualified service personnel for help.
- Do not touch the power connection with wet hands. Risk of short circuit or electric shock.
- Do not damage the power cord or leave it under pressure. Risk of fire or shock circuit.

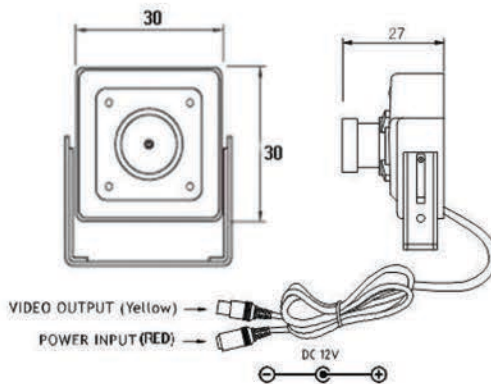

FEATURE

**1/3" COLOR SONY SUPER HAD II CCD (960H)
HIGH RESOLUTION 700TVL**

**REAR PANEL
OSD KEY**



**VIDEO/POWER
CONNECTOR**

BUILT-IN OSD KEY AT REAR PANEL
WDR, 3D-DNR(SENS-UP)
DIMENSION : 30×30 (MM)
Minimum Illumination : 0.005Lux (F:1.2)
3.6mm Fixed Lens
Power Source : DC12V (DC6.5-28V)
Standard 500mm, BNC/DC Jack
CCD MODULE SIZE: 28X28

SPECIFICATION		
Image Sensor		1/3" 960H SONY SUPER HAD II CCD
Total Pixels / Effective Pixels		1020(H) x 508(V) 1020(H) x 595(V)
Sync. Type		Internal
Scanning Frequency (Horizontal)		15.735KHz
Scanning Frequency (Vertical)		59.94Hz
Horizontal Resolution		700TVL
S/N Ratio		More than 50dB
Video Output		CVBS 1.0Vp-p (75ohm)
Min. Illumination		Color Mode:0.0003(Sens-up Auto,F1.2), B/W mode:0.00003(Sens-up Auto,F1.2)
Lens		3.6mm Fixed Lens
OSD		Built-in OSD Control key at rear panel
OSD FUNCTIONS	Exposure	ELC / ALC
	White Balance	ATW(1600°K ~ 11,000°K) / AUTO / ONE PUSH / MANUAL
	Auto Gain Control	OFF / LOW / MIDDLE / HIGH
	Electronic Shutter	1/60 ~ 1/120,000 1/50 ~ 1/120,000
	Backlight Compensation	OFF / WDR / BLC / HSBLC
	Sens-up	OFF / AUTO(X4) / MANUAL(X2 ... X 512)
	Day & Night	DAY / NIGHT / AUTO
	Digital Zoom	~ x 16
	Privacy Zone Masking	Rectangle: 8 Areas, Circle: 4 Areas, Polygon: 2 Areas
	Motion Detection	8 Regions
	3D-DNR	Level 100 Steps
	Defog	ON / OFF
	Digital Effect	OFF / V-Flip / Mirror / Rotate
OSD Language		English/Chinese,Korean,Japanese,French,Italian,Spanish,Portuguese, Dutch,German,Polish,Russian,Turkish,Arabic,Hebrew
Operation Temp. & Storage Temp.		-10℃ ~ -50℃ / -20℃ ~ -60℃
Dimension (mm)		30 × 30 (mm)
Power Supply & Power consumption		DC12V (DC6.5V ~ 28V), 70mA
Weight		Approx 60 g
Housing		ALUMINUM
Cable(option)		Standard 500mm BNC/DC Jack