



ENGLISH

Datasheet

Emergency Exit Sign, Ceiling Mount

RS Stock number: 538-8737



Specifications:

Lamp & Mode	Emergency Lumens	Weight
8 Watt M3 white luminaire economy output	80	2.90kg

Body:

Legend Panel:

Charger LED:

Lamps:

LED's:

Galvanised steel enclosure/sheet steel fascia

Flame retardant polycarbonate


Constant current with green LED for mains healthy and connected battery

8 Watt T5 fluorescent

25W chip-on-board LED

Drawing (mm):

Exit Signs

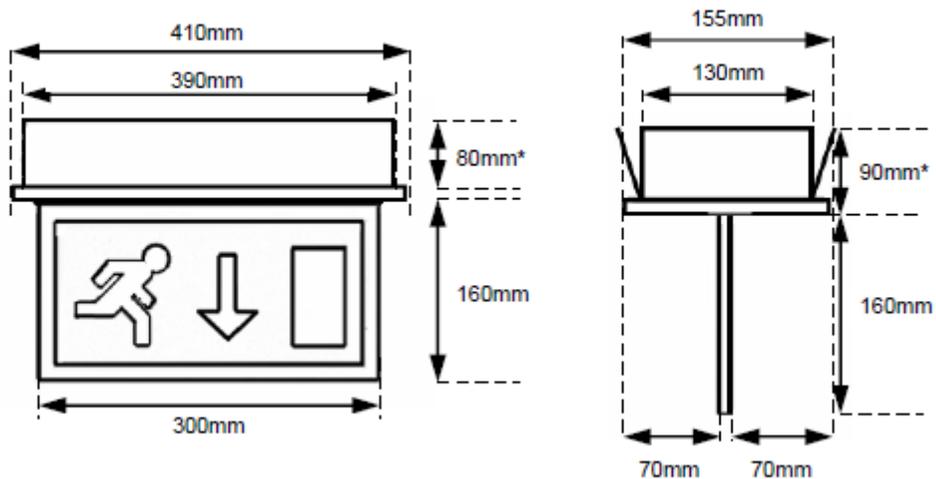

- Overall dimension is 90mm of which lip dimension is 10mm
- Cut-Out Dimensions: Length 325mm x Width 130mm (85mm minimum ceiling void.)
- Viewing Distance: 32 metres (exit versions)

Installation Instructions:

- Connect the mains cable(s), which should be a maximum of 1mm² solid core.
- The supply for a non-maintained emergency circuit must be unswitched and is connected to the unswitched input.
- The supply to a non-emergency circuit can be switched and is connected to the switched input.
- If a single unswitched supply is used for both emergency and normal use a link should be connected between the unswitched supply and switched supply terminals.
- Mark the battery pack with date of installation and connect the battery to the module.
- For testing purposes a fused spur or keyswitch should be included in the unswitched supply.