




Technical data

51204

One direction thrust ball bearings

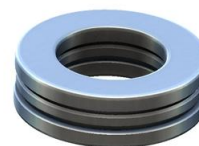

VISUAL (S)

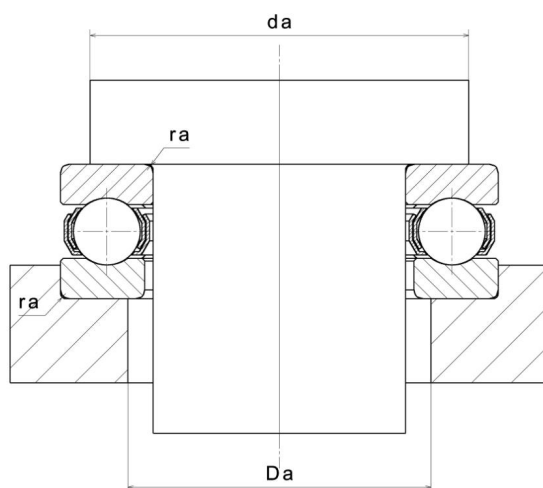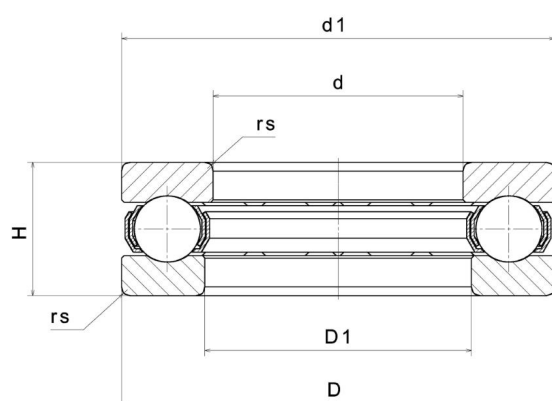

PRODUCT DEFINITION

Brand	NTN
d - Internal diameter	20 mm
D - External diameter	40 mm
T - Thrust bearing height	14 mm
rs - Min fillet radius	0,6 mm
Mass	0,081 kg

PRODUCT PERFORMANCE

Ca - Dynamic axial load rating	22300000 mN
C0a - Static axial load rating	37500000 mN
Cua - Limit axial load rating	1700000 mN
N lim - Oil lubrication limit speed	35400 °/s
N lim - Grease lubrication limit speed	24600 °/s
Tmin - Min operating temperature	233,15 °K
Tmax - Max operating temperature	393,15 °K

ABUTMENT

Da max - Max shoulder diameter OR	28 mm
da min - Min shoulder diameter IR	32 mm

