


Part Number: 192Fx35x

Type	Size	Rating	Description
LED	M14	24Vdc	LED Indicator Flat Bezel

Dimensions in mm (Not to scale)

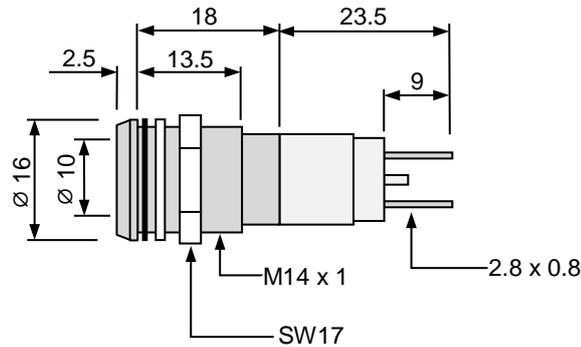

Part Number	Colour	Voltage	Typ. Current (mA)	Typ. Luminous Intensity (mcd)
192Fx351	Green	24Vdc	14	280
192Fx352	Yellow	24Vdc	15	190
192Fx353	Red	24Vdc	22	220
192Fx357	Blue	24Vdc	20	120
192Fx35W	White	24Vdc	10	250

x = 0: Satin chrome bezel    x = 1: Black chrome bezel    x = 3: Grey chrome bezel

**Notes:**

- 1 Electrical & optical data are measured at an ambient temperature of 25°C
- 2 Due to component tolerances, colour temperature variations may be observed
- 3 Storage/operating temperature range: -40 °C to +85°C
- 4 Sealed to IP67 above panel when the supplied gasket used
- 5 The plastic (polycarbonate) has limited chemical resistance
- 6 Marking: Part number, voltage rating and date code
- 7 REACH SVHC compliant
- 8 This product contains free-machining brass and is RoHS compliant via exemption clause Annex iii 6 (c) of EU Directive 2011/65/EU [Copper alloy containing lead up to 4% by weight]